

REBAR GROUNDING CLAMP, PARALLEL



CERTIFICATIONS




FEATURES

- Universal use for rebar, rods or pipes
- Lay-in feature cuts installation time
- Bronze alloy construction with Stainless Steel 304 screws
- Approved for direct burial in earth and concrete

SPECIFICATIONS

| Table 1/1 | | | | |
|----------------|----------------|---------------------------------|---------------------|--------------------|
| Catalog Number | Article Number | Ground Rod Diameter, Actual (Ø) | Water Pipe Size (Ø) | Rebar Size, Metric |
| EK16 | 710355 | 12.7 – 25.4 mm | 12.7 – 25.4 mm | 12 – 25 mm |

DIAGRAMS

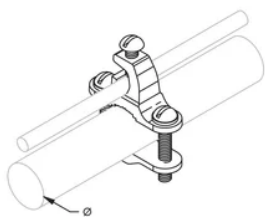

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER