



NVENT CADDY MACROFIX NON-INSULATED M8/M10



CERTIFICATIONS



FEATURES

- Plastic washer prevents screws from falling out during installation
- Combo head bolt works with slotted, hex, or Phillips drivers
- Longer ears position the screw farther from the hanger, improving tool clearance when the screw is tightened
- Combination nut can be attached to M8 or M10 threaded rod, simplifying material handling
- Screw length has been optimized to accommodate an increased pipe range, reducing inventory

SPECIFICATIONS

- Finish:** Electrogalvanized
- Material:** Steel


Table 1/2						
Catalog Number	Article Number	Outer Diameter (OD)	Pipe Size	Pipe Size Range	NB/DN	Rod Size (RS)
MFN019EG	586101	15 - 19 mm	3/8"	0.375 in	10	8, 10
MFN023EG	586102	19 - 23 mm	1/2"	0.5 in	15	8, 10

Catalog Number	Article Number	Outer Diameter (OD)	Pipe Size	Pipe Size Range	NB/DN	Rod Size(RS)
MFN029EG	586103	23 - 29 mm	3/4"	0.75 in	20	8, 10
MFN035EG	586104	29 - 35 mm	1"	1 in	25	8, 10
MFN041EG	586105	35 - 41 mm				8, 10
MFN048EG	586106	41 - 48 mm	1 1/4"	1.25 in min	32	8, 10
MFN054EG	586107	48 - 54 mm	1 1/2"	1.5 in	40	8, 10
MFN062EG	586108	54 - 62 mm	2"	2 in min	50	8, 10
MFN072EG	586109	62 - 72 mm				8, 10
MFN083EG	586110	73 - 83 mm	2 1/2"	2.5 in	65	8, 10
MFN093EG	586111	83 - 93 mm	3"	3 in	80	8, 10
MFN103EG	586112	93 - 103 mm	3 1/2"	3.5 in	90	8, 10
MFN113EG	586113	103 - 113 mm				8, 10
MFN123EG	586114	113 - 123 mm	4"	4 in	100	8, 10
MFN133EG	586115	123 - 133 mm				8, 10
MFN143EG	586116	133 - 143 mm	5"	5 in	125	8, 10
MFN153EG	586117	143 - 153 mm				8, 10
MFN165EG	586118	155 - 165 mm				8, 10
MFN175EG	586119	165 - 175 mm	6"	6 in	150	8, 10
MFN205EG	586120	195 - 205 mm				8, 10
MFN220EG	586121	210 - 220 mm	8"	8 in	200	8, 10
MFN230EG	586122	220 - 230 mm				8, 10
MFN255EG	586123	244 - 255 mm				8, 10
MFN280EG	586124	270 - 280 mm	10"	10 in	250	8, 10
MFN324EG	586125	314 - 324 mm	12"	12 in	300	8, 10

Table 2/2						
Catalog Number	Article Number	Width (W)	Thickness (T)	Screw Diameter (Sc)	Screw Length (L)	Static Load (F)
MFN019EG	586101	20 mm	1 mm	6	17mm	1000N
MFN023EG	586102	20 mm	1 mm	6	17mm	1000N
MFN029EG	586103	20 mm	1 mm	6	17mm	1000N
MFN035EG	586104	20 mm	1 mm	6	17mm	1000N
MFN041EG	586105	20 mm	1 mm	6	22mm	1000N
MFN048EG	586106	20 mm	1 mm	6	22mm	1000N
MFN054EG	586107	20 mm	1.25 mm	6	22mm	1500N

Catalog Number	Article Number	Width (W)	Thickness(T)	Screw Diameter (Sc)	ScrewLength (L)	Static Load (F)
MFN062EG	586108	20 mm	1.25 mm	6	22mm	1500N
MFN072EG	586109	20 mm	1.25 mm	6	22mm	1500N
MFN083EG	586110	23 mm	1.5 mm	6	27mm	2000N
MFN093EG	586111	23 mm	1.5 mm	6	27mm	2000N
MFN103EG	586112	23 mm	1.75 mm	6	27mm	2500N
MFN113EG	586113	23 mm	1.75 mm	6	27mm	2500N
MFN123EG	586114	23 mm	1.75 mm	6	27mm	2500N
MFN133EG	586115	23 mm	2 mm	6	27mm	3000N
MFN143EG	586116	23 mm	2 mm	6	27mm	3000N
MFN153EG	586117	25 mm	2 mm	6	27mm	3200N
MFN165EG	586118	25 mm	2 mm	6	27mm	3200N
MFN175EG	586119	25 mm	2 mm	6	27mm	3200N
MFN205EG	586120	27 mm	2.25 mm	6	32mm	3600N
MFN220EG	586121	27 mm	2.25 mm	6	32mm	3600N
MFN230EG	586122	27 mm	2.25 mm	6	32mm	3600N
MFN255EG	586123	30 mm	2.5 mm	6	32mm	4000N
MFN280EG	586124	30 mm	2.5 mm	6	32mm	4000N
MFN324EG	586125	30 mm	2.5 mm	6	32mm	4000N

DIAGRAMS

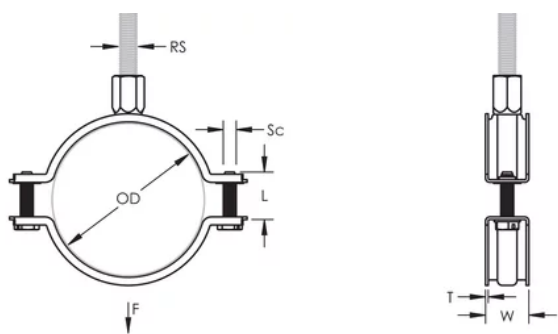

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER