



## NVENT CADDY SPEED LINK Y-TOGGLE WITH EYELET EXTENSION



### CERTIFICATIONS



### FEATURES

Attaches to clearance holes in a variety of structures or hanging devices

Ideal for supporting lighting fixtures

Y-design provides improved stability

### SPECIFICATIONS

Table 1/2

| Catalog Number | Article Number | Material | Finish            | Static Load Safety Factor | Wire Rope Diameter | Wire Rope "Y" Length (YL) |
|----------------|----------------|----------|-------------------|---------------------------|--------------------|---------------------------|
| SLD15Y500      | 195960         | Steel    | Electrogalvanized | 5:1                       | 1.5 mm             | 0.5m                      |


Table 2/2

| Catalog Number | Article Number | A     | B    | Static Load (F) | Packing Quantity |
|----------------|----------------|-------|------|-----------------|------------------|
| SLD15Y500      | 195960         | 39 mm | 5 mm | 195N            | 1.0000           |

ADDITIONAL PRODUCT DETAILS

nVent CADDY Speed Link locking device not included.

DIAGRAMS

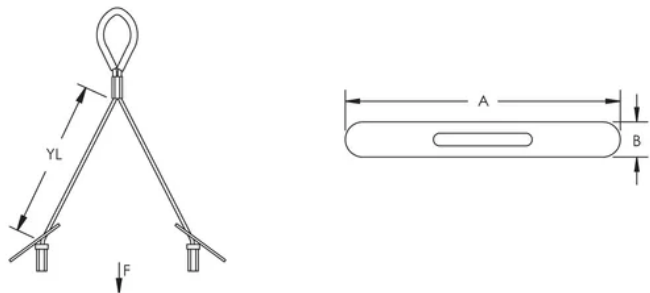

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**  
+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

**Europe**  
Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**  
Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**  
Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**