



## NVENT CADDY SPEED LINK SLS WITH HOOK



### CERTIFICATIONS



### FEATURES

Complete system includes wire, locking device and pre-assembled hook end fitting

Hooks to a wide range of nVent CADDY fasteners

Fastens to the building structure or hanging services by looping around and hooking to wire rope

Easy to remove for applications requiring maintenance

Spring latch helps provide secure connection

Insert cable through hole and use bottom side of hook as an end stop

Finger tightening of nut secures the locking device into position without tools

Installs in strut profiles without the need to insert fingers or tools into the strut

### SPECIFICATIONS

<b>Static Load Safety Factor:</b>	5:1
<b>Finish:</b>	Electrogalvanized
<b>Material:</b>	Steel;Zinc Alloy;Polypropylene
<b>Complies With:</b>	SMACNA HVAC-DCS

<b>Catalog Number</b>	<b>SLS2L 1</b>	<b>SLS2L 10</b>	<b>SLS2L 2</b>	<b>SLS2L 3</b>	<b>SLS2L 7</b>	<b>SLS3L 1</b>	<b>SLS3L 10</b>	<b>SLS3L 2</b>	<b>SLS3L 3</b>	<b>SLS3L 5</b>	<b>SLS3L 7</b>
Article Number	196741	196746	196742	196743	196745	196747	196752	196748	196749	196750	196751
Wire Rope Diameter	2 mm	2 mm	2 mm	2 mm	2 mm	3 mm	3 mm	3 mm	3 mm	3 mm	3 mm
Wire Rope Length	1m	10m	2m	3m	7m	1m	10m	2m	3m	5m	7m
A	57 mm	57 mm	57 mm	57 mm	57 mm	57.6 mm	57.6 mm	57.6 mm	57.6 mm	57.6 mm	57.6 mm
B	20 mm	20 mm	20 mm	20 mm	20 mm	23.2 mm	23.2 mm	23.2 mm	23.2 mm	23.2 mm	23.2 mm
C	5.5 mm	5.5 mm	5.5 mm	5.5 mm	5.5 mm	6.1 mm	6.1 mm	6.1 mm	6.1 mm	6.1 mm	6.1 mm
Height 1 (H1)	53mm	53mm	53mm	53mm	53mm	53mm	53mm	53mm	53mm	53mm	53mm
Height 2 (H2)	43.5mm	43.5mm	43.5mm	43.5mm	43.5mm	46.5mm	46.5mm	46.5mm	46.5mm	46.5mm	46.5mm
Thread Size (TS)	M8	M8	M8	M8	M8	M12	M12	M12	M12	M12	M12
Width (W)	16 mm	16 mm	16 mm	16 mm	16 mm	20 mm	20 mm	20 mm	20 mm	20 mm	20 mm
Hole Size (HS)	8 - 10 mm	8 - 10 mm	8 - 10 mm	8 - 10 mm	8 - 10 mm	12 - 14 mm	12 - 14 mm	12 - 14 mm	12 - 14 mm	12 - 14 mm	12 - 14 mm
Slot Size (SS)	8 x 6.5 mm - 8 x 10 mm	8 x 6.5 mm - 8 x 10 mm	8 x 6.5 mm - 8 x 10 mm	8 x 6.5 mm - 8 x 10 mm	8 x 6.5 mm - 8 x 10 mm	12 x 10 mm - 12 x 14 mm	12 x 10 mm - 12 x 14 mm	12 x 10 mm - 12 x 14 mm	12 x 10 mm - 12 x 14 mm	12 x 10 mm - 12 x 14 mm	12 x 10 mm - 12 x 14 mm
Thickness (T)	4 mm Max	4 mm Max	4 mm Max	4 mm Max	4 mm Max	6 mm Max	6 mm Max	6 mm Max	6 mm Max	6 mm Max	6 mm Max
Static Load (F)	270N	270N	270N	270N	270N	670N	670N	670N	670N	670N	670N
Packing Quantity	1.0000	1.0000	1.0000	1.0000	1.0000	1.0000	1.0000	1.0000	1.0000	1.0000	1.0000


## ADDITIONAL PRODUCT DETAILS

The 2 mm locking device is compatible with C-Channel Types E0 and E0L.

The 3 mm locking device is compatible with C-Channel Types E1, E2, E2L, E3, E4, E5, Strut Channel Type C, Slotted, Strut Channel Type A, Slotted, Strut Channel Type AS, Perforated, Strut Channel Type CC, Slotted, Strut Channel Type AA, Slotted.

Total load per wire on a multi-tier trapeze must not exceed static load.

DIAGRAMS

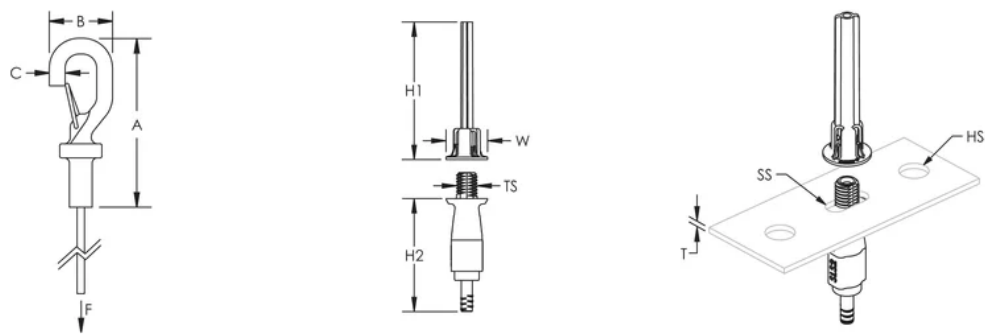

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**  
+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

**Europe**  
Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**  
Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**  
Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**