

## NVENT ERIFLEX FLEXBUS TRANSFORMER COVER IP2X FOR 1 CONDUCTOR PER PHASE



### CERTIFICATIONS



### FEATURES

Input/output for neutral/ground conductor

Resistance to solvent and hydrocarbon splashes

Installs quickly and easily

UV resistance

### SPECIFICATIONS

Table 1/2


Catalog Number	Article Number	Material	Length (L)	Working Temperature	Width (W)	Depth (D)
FLEXCOVIP2XONE	508160	Polyvinylchloride	465mm	-40 to 140°C	182mm	126mm

Table 2/2

Catalog Number	Article Number	Unit Weight
FLEXCOVIP2XONE	508160	0.53kg

## DIAGRAMS

---

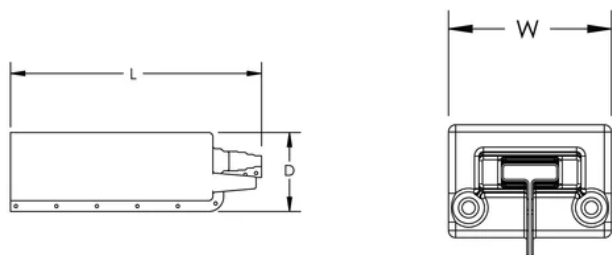

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**