


FOUR POLE DISTRIBUTION BLOCK WITH THREADED BARS, FLAT, 630 A

CATALOG NUMBER

TRC-630A

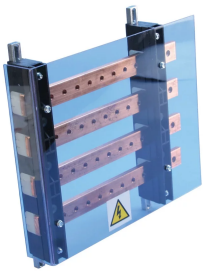

CERTIFICATIONS



FEATURES

Transparent protection cover

Bolts included for output connections

Easy accessibility for wiring

Ready to use out of the box, saving installation time and labor

RoHS compliant

PRODUCT ATTRIBUTES

Article Number: 563190

Material: Copper; Glass Fibre Reinforced Polyamide; Plexiglass

Max Working Voltage, IEC (Ui): 1000

Peak Short Circuit Current (I_{pk}): 84kA

Short Term Withstand Current (I_{cw}) 1s: 52kA

Line Side Number of Connections: 1

Load Side Number of Connections: 8

Hole Size (HS): 10mm

Thread Size (TS): M8

Depth (D): 60mm

Height (H): 338 – 390mm

Width (W): 340mm

A: 290mm

Unit Weight: 4.8kg


Flammability Rating: UL® 94V-0

Complies With: IEC® 60439.1; IEC® 61439.1; IEC® 60695-2-11 (Glow Wire Test 960 °C)

ADDITIONAL PRODUCT DETAILS

Line side and load side number of connections are per pole.

DIAGRAMS

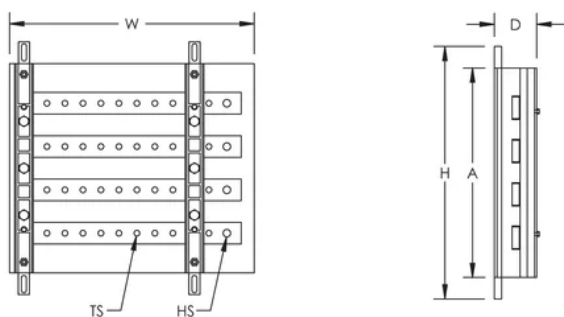

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER