

NVENT CADDY SPEED LINK SLK WITH WEDGE ANCHOR



FEATURES

Complete system includes wire, locking device and wedge anchor from fischerwerke GmbH &Co. KG

Quickly and easily attaches into cracked and non-cracked concrete

No special tools required

ETA 06/0175 approval available from fischerwerke GmbH &Co. KG

SPECIFICATIONS

Wire Rope Diameter:	2 mm
Static Load Safety Factor:	5:1
Drill Bit Diameter:	6mm
Drill Hole Depth:	31mm
Finish:	Electrogalvanized
Material:	Steel;Polypropylene;Zinc Alloy
Embedment Depth:	25 mm Min


Table 1/2

Catalog Number	Article Number	Wire Rope Length	Length (L)	Height (H)	Width (W)	Thickness (T)
SLK2L2WA6	196734	2m	54 mm	55 mm	19 mm	12.5 mm
SLK2L3WA6	196735	3m	54 mm	55 mm	19 mm	12.5 mm
SLK2L5WA6	196736	5m	63.5 mm	55 mm	19 mm	12.5 mm

Table 2/2

Catalog Number	Article Number	Angle (a)	Static Load (F)
SLK2L2WA6	196734	90 ° Max	300N
SLK2L3WA6	196735	90 ° Max	300N
SLK2L5WA6	196736	90 ° Max	440N

DIAGRAMS

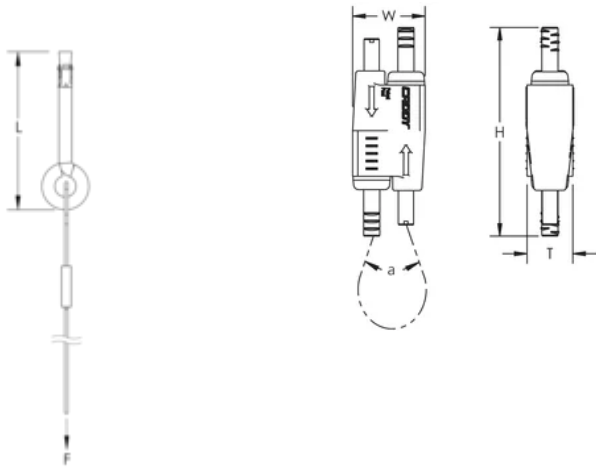

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com **CADDY ERICO HOFFMAN RAYCHEM SCHROFF**
TRACER