



NVENT CADDY MACROFIX NON-INSULATED M8/M10



CERTIFICATIONS



FEATURES

Plastic washer prevents screws from falling out during installation

Combo head bolt works with slotted, hex, or Phillips drivers

Longer ears position the screw farther from the hanger, improving tool clearance when the screw is tightened

Combination nut can be attached to M8 or M10 threaded rod, simplifying material handling

Screw length has been optimized to accommodate an increased pipe range, reducing inventory

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel

Table 1/2


Catalog Number	Article Number	Outer Diameter (OD)	Pipe Size	NB/DN	Rod Size (RS)	Width (W)
MFN019EG	586101	15 - 19 mm	3/8"	10	8, 10	20 mm
MFN023EG	586102	19 - 23 mm	1/2"	15	8, 10	20 mm

Catalog Number	Article Number	Outer Diameter (OD)	Pipe Size	NB/DN	Rod Size(RS)	Width (W)
MFN029EG	586103	23 - 29 mm	3/4"	20	8, 10	20 mm
MFN035EG	586104	29 - 35 mm	1"	25	8, 10	20 mm
MFN041EG	586105	35 - 41 mm			8, 10	20 mm
MFN048EG	586106	41 - 48 mm	1 1/4"	32	8, 10	20 mm
MFN054EG	586107	48 - 54 mm	1 1/2"	40	8, 10	20 mm
MFN062EG	586108	54 - 62 mm	2"	50	8, 10	20 mm
MFN072EG	586109	62 - 72 mm			8, 10	20 mm
MFN083EG	586110	73 - 83 mm	2 1/2"	65	8, 10	23 mm
MFN093EG	586111	83 - 93 mm	3"	80	8, 10	23 mm
MFN103EG	586112	93 - 103 mm	3 1/2"	90	8, 10	23 mm
MFN113EG	586113	103 - 113 mm			8, 10	23 mm
MFN123EG	586114	113 - 123 mm	4"	100	8, 10	23 mm
MFN133EG	586115	123 - 133 mm			8, 10	23 mm
MFN143EG	586116	133 - 143 mm	5"	125	8, 10	23 mm
MFN153EG	586117	143 - 153 mm			8, 10	25 mm
MFN165EG	586118	155 - 165 mm			8, 10	25 mm
MFN175EG	586119	165 - 175 mm	6"	150	8, 10	25 mm
MFN205EG	586120	195 - 205 mm			8, 10	27 mm
MFN220EG	586121	210 - 220 mm	8"	200	8, 10	27 mm
MFN230EG	586122	220 - 230 mm			8, 10	27 mm
MFN255EG	586123	244 - 255 mm			8, 10	30 mm
MFN280EG	586124	270 - 280 mm	10"	250	8, 10	30 mm
MFN324EG	586125	314 - 324 mm	12"	300	8, 10	30 mm

Table 2/2					
Catalog Number	Article Number	Thickness (T)	Screw Diameter (Sc)	Screw Length (L)	Static Load (F)
MFN019EG	586101	1 mm	6	17mm	1000N
MFN023EG	586102	1 mm	6	17mm	1000N
MFN029EG	586103	1 mm	6	17mm	1000N
MFN035EG	586104	1 mm	6	17mm	1000N
MFN041EG	586105	1 mm	6	22mm	1000N
MFN048EG	586106	1 mm	6	22mm	1000N
MFN054EG	586107	1.25 mm	6	22mm	1500N

CatalogNumber	Article Number	Thickness (T)	ScrewDiameter (Sc)	Screw Length (L)	Static Load (F)
MFN062EG	586108	1.25 mm	6	22mm	1500N
MFN072EG	586109	1.25 mm	6	22mm	1500N
MFN083EG	586110	1.5 mm	6	27mm	2000N
MFN093EG	586111	1.5 mm	6	27mm	2000N
MFN103EG	586112	1.75 mm	6	27mm	2500N
MFN113EG	586113	1.75 mm	6	27mm	2500N
MFN123EG	586114	1.75 mm	6	27mm	2500N
MFN133EG	586115	2 mm	6	27mm	3000N
MFN143EG	586116	2 mm	6	27mm	3000N
MFN153EG	586117	2 mm	6	27mm	3200N
MFN165EG	586118	2 mm	6	27mm	3200N
MFN175EG	586119	2 mm	6	27mm	3200N
MFN205EG	586120	2.25 mm	6	32mm	3600N
MFN220EG	586121	2.25 mm	6	32mm	3600N
MFN230EG	586122	2.25 mm	6	32mm	3600N
MFN255EG	586123	2.5 mm	6	32mm	4000N
MFN280EG	586124	2.5 mm	6	32mm	4000N
MFN324EG	586125	2.5 mm	6	32mm	4000N

DIAGRAMS

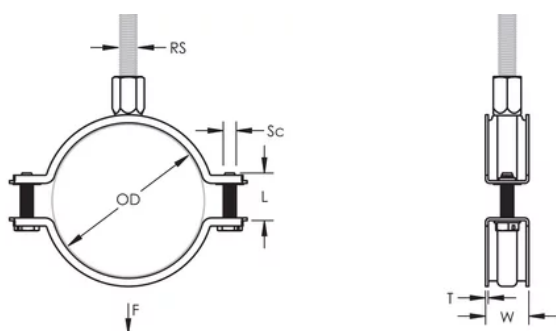

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER