



## NVENT CADDY SPEED LINK SLK WITH DECKING HOOK



### CERTIFICATIONS



### FEATURES

Complete system includes wire, locking device and pre-assembled decking hook end fitting

Quickly and easily attaches to hollow metal decking

Spring-loaded ends snap into decking hole and lock into place

Innovative design helps protect the wire from sharp edges of decking hole, minimizing risk of damage to wire

### SPECIFICATIONS

<b>Static Load Safety Factor:</b>	5:1
<b>Finish:</b>	Electrogalvanized
<b>Material:</b>	Steel;Zinc Alloy;Polypropylene
<b>Complies With:</b>	SMACNA HVAC-DCS

Table 1/2

Catalog Number	Article Number	Wire Rope Diameter	Wire Rope Length	Roof Decking Sheet Thickness	A	Hole Size (HS)
SLK15L1DH	196676	1.5 mm	1m	1.5 mm Max	9.2 mm	8 mm

Catalog Number	Article Number	Wire Rope Diameter	Wire Rope Length	RoofDecking Sheet Thickness	A	Hole Size (HS)
SLK15L2DH	196677	1.5 mm	2m	1.5 mm Max	9.2 mm	8 mm
SLK15L3DH	196504	1.5 mm	3m	1.5 mm Max	9.2 mm	8 mm
SLK15L5DH	196505	1.5 mm	5m	1.5 mm Max	9.2 mm	8 mm
SLK2L3DH	196532	2 mm	3m	1.5 mm Max	9.2 mm	8 mm
SLK2L5DH	196533	2 mm	5m	1.5 mm Max	9.2 mm	8 mm
SLK2L7DH	196534	2 mm	7m	1.5 mm Max	9.2 mm	8 mm

Table 2/2

Catalog Number	Article Number	Static Load (F)
SLK15L1DH	196676	195N
SLK15L2DH	196677	195N
SLK15L3DH	196504	195N
SLK15L5DH	196505	195N
SLK2L3DH	196532	440N
SLK2L5DH	196533	440N
SLK2L7DH	196534	440N


**Thickness (T):** 12.5 mm  
**Width (W):** 19 mm  
**Height (H):** 55 mm  
**Angle (a):** 90 ° Max

## ADDITIONAL PRODUCT DETAILS

Load rating is only applicable if the load-bearing capacity of the supporting element (steel decking) is adequate.

Check with deck manufacturer for recommended load capacity.

## DIAGRAMS

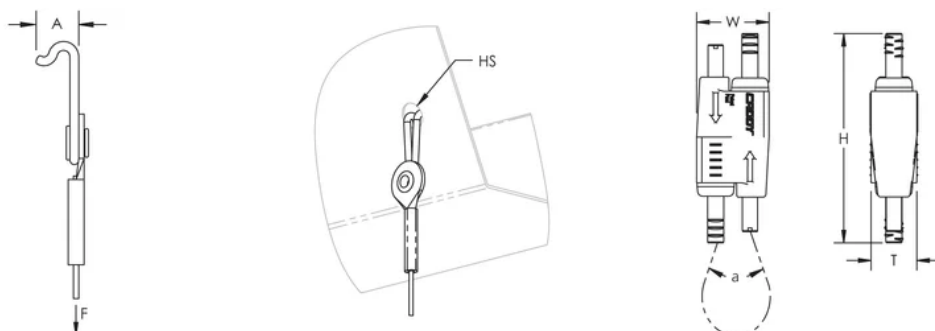

**WARNING**

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

**Europe**

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**