

2HPS TWO HOLE PIPE STRAP



FEATURES

Light duty support of pipe

Attaches directly to the face of a horizontal or vertical structural member

SPECIFICATIONS

Finish: Pregalvanized

Material: Steel

Table 1/2


Catalog Number	Article Number	Pipe Size	Pipe Size Range	NB/DN	Outer Diameter (OD)	Hole Size (HS)
008017EG	400678	3/8"	0.375 in	10	17.2 mm	7 mm
008021EG	400679	1/2"	0.5 in	15	21.3 mm	7 mm
008027EG	400680	3/4"	0.75 in	20	26.9 mm	7 mm
008034EG	400681	1"	1 in	25	33.7 mm	7 mm
008042EG	400682	1 1/4"	1.25 in min	32	42.4 mm	7 mm
008048EG	400683	1 1/2"	1.5 in	40	48.3 mm	7 mm
008060EG	400684	2"	2 in min	50	60.3 mm	7 mm

Table 2/2

Catalog Number	Article Number	Width (W)	Thickness (T)
008017EG	400678	20 mm	1 mm

Catalog Number	Article Number	Width (W)	Thickness (T)
008021EG	400679	20 mm	1 mm
008027EG	400680	20 mm	1 mm
008034EG	400681	20 mm	1 mm
008042EG	400682	20 mm	1 mm
008048EG	400683	20 mm	1 mm
008060EG	400684	20 mm	1 mm

DIAGRAMS

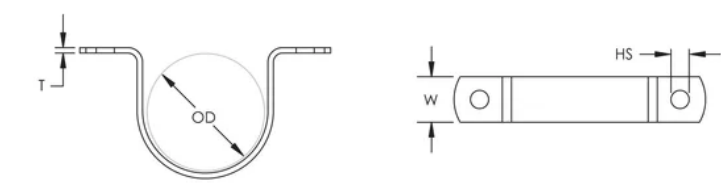

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500