



## NVENT CADDY SUPERKLIP



### FEATURES

Closes and locks automatically when the pipe, tube or cable is inserted

One-piece clamp for fast and convenient installation

Fasten with either wood screw, dual threaded screw with or without collar, nail with collar, threaded rod, mounting plate or shot-fire bracket

### SPECIFICATIONS

**Material:** Xenoy®

**Temperature:** -25 to 90 °C

Table 1/2


Catalog Number	Article Number	Outer Diameter (OD)	Pipe Size	Copper Tube Size	B	C
389017	389017	7.8 - 9.5 mm		1/4"	17.1 mm	26.4 mm
389018	389018	9.5 - 11.8 mm		1/4"	17.1 mm	26.4 mm
389003	389003	16.8 - 19.5 mm	3/8"	5/8"	20 mm	35.4 mm
389001	389001	11.8 - 14.3 mm		3/8"	17.2 mm	29.9 mm
389004	389004	19.5 - 21.8 mm	1/2"		20 mm	39.4 mm
389002	389002	14.3 - 16.8 mm		1/2"	19.5 mm	32 mm
389005	389005	21.8 - 24.8 mm		3/4"	20 mm	42 mm
389006	389006	24.8 - 27.8 mm	3/4"		20.2 mm	45.1 mm
389007	389007	27.8 - 31.2 mm		1"	20.2 mm	48.9 mm

Catalog Number	Article Number	Outer Diameter (OD)	Pipe Size	Copper Tube Size	B	C
389008	389008	31.2 - 35.5 mm	1"	1 1/4"	21 mm	54.4 mm
389009	389009	35.5 - 39.5 mm		1 1/4"	21 mm	59.4 mm
389011	389011	39.5 - 43.5 mm	1 1/4"	1 1/2"	21 mm	64.2 mm
389013	389013	50.5 - 55.5 mm		2"	23 mm	78.7 mm

Table 2/2

Catalog Number	Article Number	Static Load (F)
389017	389017	135N
389018	389018	150N
389003	389003	190N
389001	389001	160N
389004	389004	200N
389002	389002	175N
389005	389005	215N
389006	389006	240N
389007	389007	260N
389008	389008	300N
389009	389009	320N
389011	389011	360N
389013	389013	400N

## DIAGRAMS

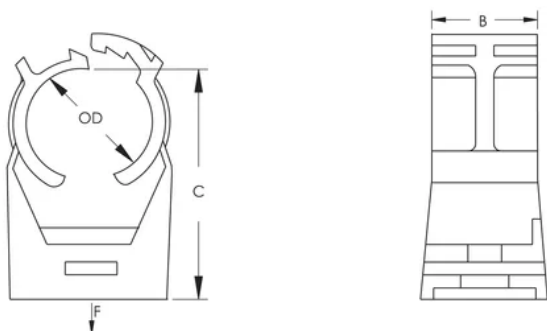

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**