


MULTIPACPRO 19" CHASSIS BASIC KIT

Such a kit enables a customer to configure the 3 different top / bottom covers.

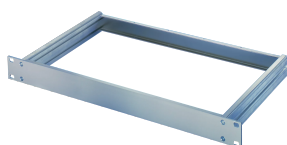

CERTIFICATIONS



FEATURES

For non-standardized assemblies (1 ... 5 U) and standardized assemblies (1, 2 U) conforming to IEC 60297-3-105

Frame consists of two lateral parts and front/rear panel

Material: aluminium

Select further components (Accessories)

SPECIFICATIONS

Table 1/2

Catalog Number	Usable Width	EMC Shielding	Product Type	Product Family	Type	Rack Height
20860-201	403 mm	No (Retrofittable)	Subrack/Chassis	MultipacPRO	Configurable	1 U
20860-202	403 mm	No (Retrofittable)	Subrack/Chassis	MultipacPRO	Configurable	1 U
20860-203	403 mm	No (Retrofittable)	Subrack/Chassis	MultipacPRO	Configurable	1 U
20860-204	4 mm	No (Retrofittable)	Subrack/Chassis	MultipacPRO	Configurable	1 U

Catalog Number	UsableWidth	EMC Shielding	ProductType	Product Family	Type	Rack Height
20860-205	4 mm	No (Retrofittable)	Subrack/Chassis	MultipacPRO	Configurable	1 U
20860-210	403 mm	No (Retrofittable)	Subrack/Chassis	MultipacPRO	Configurable	2 U
20860-211	403 mm	No (Retrofittable)	Subrack/Chassis	MultipacPRO	Configurable	2 U
20860-212	403 mm	No (Retrofittable)	Subrack/Chassis	MultipacPRO	Configurable	2 U
20860-213	4 mm	No (Retrofittable)	Subrack/Chassis	MultipacPRO	Configurable	2 U
20860-214	4 mm	No (Retrofittable)	Subrack/Chassis	MultipacPRO	Configurable	2 U
20860-219	403 mm	No (Retrofittable)	Subrack/Chassis	MultipacPRO	Configurable	3 U
20860-220	403 mm	No (Retrofittable)	Subrack/Chassis	MultipacPRO	Configurable	3 U
20860-221	403 mm	No (Retrofittable)	Subrack/Chassis	MultipacPRO	Configurable	3 U
20860-222	403 mm	No (Retrofittable)	Subrack/Chassis	MultipacPRO	Configurable	3 U
20860-228	403 mm	No (Retrofittable)	Subrack/Chassis	MultipacPRO	Configurable	4 U
20860-229	403 mm	No (Retrofittable)	Subrack/Chassis	MultipacPRO	Configurable	4 U
20860-230	403 mm	No (Retrofittable)	Subrack/Chassis	MultipacPRO	Configurable	4 U
20860-231	403 mm	No (Retrofittable)	Subrack/Chassis	MultipacPRO	Configurable	4 U
20860-240	403 mm	No (Retrofittable)	Subrack/Chassis	MultipacPRO	Configurable	5 U

Table 2/2

Catalog Number	Complies With	Mounting	Depth	Certifications
20860-201	IEC 60297-3-100	Rack	220 mm	RoHS
20860-202	IEC 60297-3-100	Rack	280 mm	RoHS
20860-203	IEC 60297-3-100	Rack	340 mm	RoHS
20860-204	IEC 60297-3-100	Rack	400 mm	
20860-205	IEC 60297-3-100	Rack	460 mm	
20860-210	IEC 60297-3-100	Rack	220 mm	RoHS
20860-211	IEC 60297-3-100	Rack	280 mm	RoHS

Catalog Number	Complies With	Mounting	Depth	Certifications
20860-212	IEC 60297-3-100	Rack	340 mm	RoHS
20860-213	IEC 60297-3-100	Rack	400 mm	
20860-214	IEC 60297-3-100	Rack	460 mm	
20860-219	IEC 60297-3-100	Rack	280 mm	RoHS
20860-220	IEC 60297-3-100	Rack	340 mm	RoHS
20860-221	IEC 60297-3-100	Rack	400 mm	RoHS
20860-222	IEC 60297-3-100	Rack	460 mm	RoHS
20860-228	IEC 60297-3-100	Rack	280 mm	RoHS
20860-229	IEC 60297-3-100	Rack	340 mm	RoHS
20860-230	IEC 60297-3-100	Rack	400 mm	RoHS
20860-231	IEC 60297-3-100	Rack	460 mm	RoHS
20860-240	IEC 60297-3-100	Rack	460 mm	RoHS

ADDITIONAL PRODUCT DETAILS

Please order mounting plate, cover and base plates, handles, telescopic slides separately.

Dimensions h = clear mounting height = H-8.1 mm, b = clear mounting width = 403 mm.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:
nVent.com **CADDY ERICO HOFFMAN RAYCHEM SCHROFF**
TRACER