



CS812 CABLE/CONDUIT TO STUD ATTACHMENT



CERTIFICATIONS



FEATURES

- Accommodates EMT conduit and MC/AC cable
- Easily locate the fastener on the stud, keeping your conduit in line with box knock out and C-series brackets
- For wood or metal stud
- Eliminates offset bending of conduit
- Compliant with NEC® Article 358.30(A), which requires conduit support within 36" of an electrical box
- Compliant with CEC Rule 12-1404, which requires conduit support within 1 m of an electrical box
- Compliant with CEC Rule 12-618, which requires support of armoured cable within 300 mm (12") of an electrical box


SPECIFICATIONS

- Finish:** nVent CADDY Armour
- Material:** Spring Steel

Table 1/1				
Catalog Number	Article Number	Outer Diameter (OD)	Box Depth	Packing Quantity
CS812	176910	18 - 30 mm	38mm	1.0000

Catalog Number	Article Number	Outer Diameter (OD)	Box Depth	Packing Quantity
CS812D		18 - 30 mm	54mm	1.0000
CS16		30 - 35 mm	54mm	1.0000

DIAGRAMS

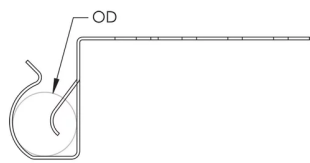

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America +1.800.753.9221 Option 1 – Customer Care Option 2 – Technical Support	Europe Netherlands: +31 800-0200135 France: +33 800 901 793	Europe Germany: 800 1890272 Other Countries: +31 13 5835404	APAC Shanghai: + 86 21 2412 1618/19 Sydney: +61 2 9751 8500
---	--	--	--