


MOBILE BASE FOR OPEN FRAME RACKS 2-POST, BLACK, STEEL

CATALOG NUMBER

A19MB1000

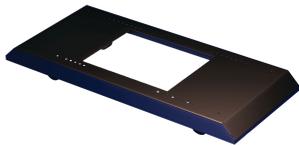

The Mobile Base for Open-Frame Racks provide stability and mobility to open-frame racks. It has models for both 19-in. 2- and 4-Post Open Frame Racks. This product mounts to the bottom of the racks previously mentioned. It includes four non-locking casters but will also accept standard levelers. Please note, catalog number PMBLM12 must be ordered separately, however the mounting hardware is included.

FEATURES

The Mobile Base for Open-Frame Racks provide stability and mobility to open-frame racks

It has models for both 19-in. 2- and 4-Post Open Frame Racks

This product mounts to the bottom of the racks previously mentioned. It includes four non-locking casters but will also accept standard levelers

Please note, catalog number PMBLM12 must be ordered separately, however the mounting hardware is included

PRODUCT ATTRIBUTES

Article Number: 13774

Material: Mild Steel

Finish: Powder Coated

Color: Jet Black

Color Code: RAL 9005

Thickness: 2.66mm

Fits: 4-post open-frame racks with depth adjustable between 17.7- and 29.5-in. (450- and 750-mm) in 0.98-in. (25-mm) increments

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction,

property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:
[nVent.com](https://www.nvent.com) **CADDY ERICO HOFFMAN RAYCHEM SCHROFF**
TRACER

© 2025 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.