



MULTI-FUNCTION C-CLAMP



FEATURES

Multi-functional beam clamp

Use with Cable/Conduit/Pipe Clamp or Square Washer for Multi-Function C-Clamp

SPECIFICATIONS

Finish: Hot-Dip Galvanized

Table 1/2

Catalog Number	Article Number	E-Number	Material	Flange Thickness (FT)	Hole Size (HS)	Screw Diameter (Sc)
C20HD	336100	3535807	Steel	4 - 20 mm	14 mm	6
C20S4	336130	3535811	Stainless Steel 304 (EN 1.4301)	4 - 20 mm	14 mm	6
C30HD	336110	3535808	Steel	17 - 30 mm	14 mm	8
C30S4	336140	3535812	Stainless Steel 304 (EN 1.4301)	17 - 30 mm	14 mm	8
C45HD	336120	3535809	Steel	30 - 44 mm	14 mm	8
C45S4	336150	3535813	Stainless Steel 304 (EN 1.4301)	30 - 44 mm	14 mm	8

Table 2/2


Catalog Number	Article Number	E-Number	Screw Length (L)	Torque (TQ)	Static Load (F)
----------------	----------------	----------	------------------	-------------	-----------------

C20HD	336100	3535807	25mm	3 N·m	1100N
C20S4	336130	3535811	25mm	3 N·m	1100N
C30HD	336110	3535808	30mm	3 N·m	1100N
C30S4	336140	3535812	30mm	3 N·m	1100N
C45HD	336120	3535809	30mm	3 N·m	1100N
C45S4	336150	3535813	30mm	3 N·m	1100N

ADDITIONAL PRODUCT DETAILS

Setscrew must be tightened and torqued onto the sloped side of the I-beam.

DIAGRAMS

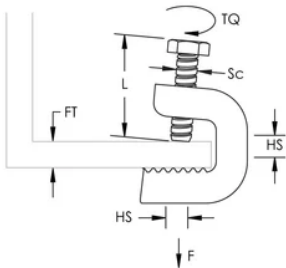

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America
+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe
Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe
Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC
Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500