




NVENT CADDY MACROFIX INSULATED M8

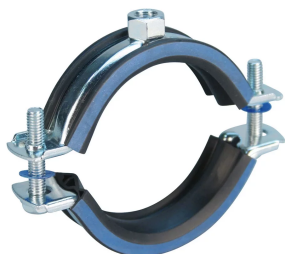

CERTIFICATIONS



FEATURES

Return-lip on the hanger prevents the rubber from detaching, eliminating rework during installation

Plastic washer prevents screws from falling out during installation

Combo head bolt works with slotted, hex, or Phillips drivers

Longer ears position the screw farther from the hanger, improving tool clearance when the screw is tightened

Screw length has been optimized to accommodate an increased pipe range, reducing inventory

Category II noise reduction according to DIN EN ISO 3822-1

Compliant for sound insulation design according to DIN 4109

Reaction-to-fire classification is "E" in compliance with DIN EN 13501-1

SPECIFICATIONS

Finish: Electrogalvanized

Material: EPDM-SBR Rubber;Steel

Temperature: -50 to 110 °C

Table 1/3						
Catalog Number	Article Number	E-Number	Outer Diameter (OD)	Pipe Size	NB/DN	Rod Size (RS)
MFE015	586201	3532841	11 - 15 mm	1/4"	8	8
MFE019	586202	3532842	15 - 19 mm	3/8"	10	8
MFE025	586203	3532843	19 - 25 mm	1/2"	15	8
MFE031	586204	3532844	25 - 31 mm	3/4"	20	8
MFE037	586205	3532845	31 - 37 mm	1"	25	8
MFE044	586206	3532846	37 - 44 mm	1 1/4"	32	8
MFE050	586207	3532847	44 - 50 mm	1 1/2"	40	8
MFE058	586208	3532848	50 - 58 mm			8
MFE068	586209	3532849	58 - 68 mm	2"	50	8


Table 2/3						
Catalog Number	Article Number	E-Number	Width (W)	Thickness (T)	Screw Diameter (Sc)	Screw Length (L)
MFE015	586201	3532841	20 mm	1 mm	6	17mm
MFE019	586202	3532842	20 mm	1 mm	6	17mm
MFE025	586203	3532843	20 mm	1 mm	6	22mm
MFE031	586204	3532844	20 mm	1 mm	6	22mm
MFE037	586205	3532845	20 mm	1 mm	6	22mm
MFE044	586206	3532846	20 mm	1 mm	6	27mm
MFE050	586207	3532847	20 mm	1.25 mm	6	27mm
MFE058	586208	3532848	20 mm	1.25 mm	6	27mm
MFE068	586209	3532849	20 mm	1.25 mm	6	32mm

Table 3/3			
Catalog Number	Article Number	E-Number	Static Load (F)
MFE015	586201	3532841	1000N
MFE019	586202	3532842	1000N
MFE025	586203	3532843	1000N
MFE031	586204	3532844	1000N
MFE037	586205	3532845	1000N
MFE044	586206	3532846	1000N
MFE050	586207	3532847	1500N
MFE058	586208	3532848	1500N
MFE068	586209	3532849	1500N

ADDITIONAL PRODUCT DETAILS

Lining is EPDM rubber.

DIAGRAMS

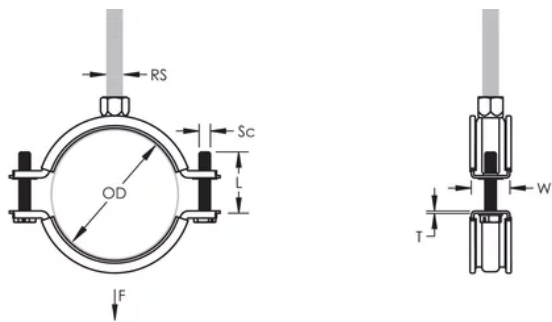

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America
+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe
Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe
Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC
Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER