



NVENT CADDY MACROFIX NON-INSULATED M8/M10



CERTIFICATIONS



FEATURES

Plastic washer prevents screws from falling out during installation

Combo head bolt works with slotted, hex, or Phillips drivers

Longer ears position the screw farther from the hanger, improving tool clearance when the screw is tightened

Combination nut can be attached to M8 or M10 threaded rod, simplifying material handling

Screw length has been optimized to accommodate an increased pipe range, reducing inventory

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel

Table 1/3

Catalog Number	Article Number	E-Number	Outer Diameter (OD)	Pipe Size	NB/DN	Rod Size (RS)
MFN019EG	586101	3536031	15 - 19 mm	3/8"	10	8, 10
MFN023EG	586102	3536032	19 - 23 mm	1/2"	15	8, 10

Catalog Number	Article Number	E-Number	Outer Diameter (OD)	Pipe Size	NB/DN	Rod Size(RS)
MFN029EG	586103	3536033	23 - 29 mm	3/4"	20	8, 10
MFN035EG	586104	3536034	29 - 35 mm	1"	25	8, 10
MFN041EG	586105	3536035	35 - 41 mm			8, 10
MFN048EG	586106	3536036	41 - 48 mm	1 1/4"	32	8, 10
MFN054EG	586107	3536037	48 - 54 mm	1 1/2"	40	8, 10
MFN062EG	586108	3536038	54 - 62 mm	2"	50	8, 10
MFN072EG	586109	3536039	62 - 72 mm			8, 10
MFN083EG	586110	3536041	73 - 83 mm	2 1/2"	65	8, 10
MFN093EG	586111	3536042	83 - 93 mm	3"	80	8, 10
MFN103EG	586112	3536043	93 - 103 mm	3 1/2"	90	8, 10
MFN113EG	586113	3536044	103 - 113 mm			8, 10
MFN123EG	586114	3536045	113 - 123 mm	4"	100	8, 10
MFN133EG	586115	3536046	123 - 133 mm			8, 10
MFN143EG	586116	3536047	133 - 143 mm	5"	125	8, 10
MFN153EG	586117	3533381	143 - 153 mm			8, 10
MFN165EG	586118	3533382	155 - 165 mm			8, 10
MFN175EG	586119	3533383	165 - 175 mm	6"	150	8, 10
MFN205EG	586120	3533384	195 - 205 mm			8, 10
MFN220EG	586121	3533385	210 - 220 mm	8"	200	8, 10
MFN230EG	586122	3533386	220 - 230 mm			8, 10
MFN255EG	586123	3533387	244 - 255 mm			8, 10
MFN280EG	586124	3533388	270 - 280 mm	10"	250	8, 10
MFN324EG	586125	3533389	314 - 324 mm	12"	300	8, 10

Table 2/3						
Catalog Number	Article Number	E-Number	Width (W)	Thickness (T)	Screw Diameter (Sc)	Screw Length (L)
MFN019EG	586101	3536031	20 mm	1 mm	6	17mm
MFN023EG	586102	3536032	20 mm	1 mm	6	17mm
MFN029EG	586103	3536033	20 mm	1 mm	6	17mm
MFN035EG	586104	3536034	20 mm	1 mm	6	17mm
MFN041EG	586105	3536035	20 mm	1 mm	6	22mm
MFN048EG	586106	3536036	20 mm	1 mm	6	22mm
MFN054EG	586107	3536037	20 mm	1.25 mm	6	22mm


Catalog Number	Article Number	E-Number	Width (W)	Thickness(T)	Screw Diameter (Sc)	ScrewLength (L)
MFN062EG	586108	3536038	20 mm	1.25 mm	6	22mm
MFN072EG	586109	3536039	20 mm	1.25 mm	6	22mm
MFN083EG	586110	3536041	23 mm	1.5 mm	6	27mm
MFN093EG	586111	3536042	23 mm	1.5 mm	6	27mm
MFN103EG	586112	3536043	23 mm	1.75 mm	6	27mm
MFN113EG	586113	3536044	23 mm	1.75 mm	6	27mm
MFN123EG	586114	3536045	23 mm	1.75 mm	6	27mm
MFN133EG	586115	3536046	23 mm	2 mm	6	27mm
MFN143EG	586116	3536047	23 mm	2 mm	6	27mm
MFN153EG	586117	3533381	25 mm	2 mm	6	27mm
MFN165EG	586118	3533382	25 mm	2 mm	6	27mm
MFN175EG	586119	3533383	25 mm	2 mm	6	27mm
MFN205EG	586120	3533384	27 mm	2.25 mm	6	32mm
MFN220EG	586121	3533385	27 mm	2.25 mm	6	32mm
MFN230EG	586122	3533386	27 mm	2.25 mm	6	32mm
MFN255EG	586123	3533387	30 mm	2.5 mm	6	32mm
MFN280EG	586124	3533388	30 mm	2.5 mm	6	32mm
MFN324EG	586125	3533389	30 mm	2.5 mm	6	32mm

Table 3/3

Catalog Number	Article Number	E-Number	Static Load (F)
MFN019EG	586101	3536031	1000N
MFN023EG	586102	3536032	1000N
MFN029EG	586103	3536033	1000N
MFN035EG	586104	3536034	1000N
MFN041EG	586105	3536035	1000N
MFN048EG	586106	3536036	1000N
MFN054EG	586107	3536037	1500N
MFN062EG	586108	3536038	1500N
MFN072EG	586109	3536039	1500N
MFN083EG	586110	3536041	2000N
MFN093EG	586111	3536042	2000N
MFN103EG	586112	3536043	2500N
MFN113EG	586113	3536044	2500N

Catalog Number	Article Number	E-Number	Static Load (F)
MFN123EG	586114	3536045	2500N
MFN133EG	586115	3536046	3000N
MFN143EG	586116	3536047	3000N
MFN153EG	586117	3533381	3200N
MFN165EG	586118	3533382	3200N
MFN175EG	586119	3533383	3200N
MFN205EG	586120	3533384	3600N
MFN220EG	586121	3533385	3600N
MFN230EG	586122	3533386	3600N
MFN255EG	586123	3533387	4000N
MFN280EG	586124	3533388	4000N
MFN324EG	586125	3533389	4000N

DIAGRAMS

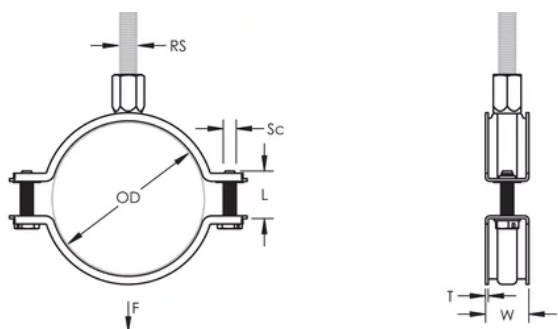

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER