

NVENT CADDY MACROFIX PLUS KOMBI WITH COMBINATION NUT



FEATURES

Includes easy closing mechanism

Age-resistant lining

Category II noise reduction according to DIN EN ISO 3822-1

Compliant for sound insulation design according to DIN 4109

Reaction-to-fire classification is "E" in compliance with DIN EN 13501-1

SPECIFICATIONS

Rod Size (RS):	M8;M10;1/2"
Color:	Black
Finish:	Electrogalvanized
Material:	Steel;EPDM-SBR Rubber
Temperature:	-50 to 110 °C

Table 1/2

Catalog Number	Article Number	Outer Diameter (OD)	Pipe Size	Pipe Size Range	NB/DN	Width (W)
MPK031	586754	25 - 31 mm	3/4"	0.75 in	20	20 mm
MPK037	586755	31 - 37 mm	1"	1 in	25	20 mm
MPK044	586756	37 - 44 mm	1 1/4"	1.25 in min	32	20 mm
MPK051	586757	45 - 51 mm	1 1/2"	1.5 in	40	21 mm
MPK058	586758	50 - 58 mm				21 mm


Catalog Number	Article Number	Outer Diameter (OD)	Pipe Size	Pipe Size Range	NB/DN	Width (W)
MPK068	586759	58 - 68 mm	2" - 5"	2 – 5 in	50	21 mm
MPK078	586760	68 - 78 mm	2 1/2"	2.5 in	65	23 mm
MPK088	586761	78 - 88 mm				23 mm
MPK098	586762	88 - 98 mm	3"	3 in	80	23 mm
MPK118	586763	108 - 118 mm	4"	4 in	100	23 mm
MPK138	586764	128 - 138 mm				23 mm
MPK148	586765	138 - 148 mm	5"	5 in	125	25 mm
MPK160	586766	150 - 160 mm				25 mm
MPK170	586767	160 - 170 mm	6"	6 in	150	25 mm
MPK201	586768	190 - 200 mm				27 mm

Table 2/2						
Catalog Number	Article Number	Thickness (T)	Screw Diameter (Sc)	Screw Length (L)	Static Load (F)	Unit Weight
MPK031	586754	1 mm	6 mm	32mm	1000N	0.11 kg
MPK037	586755	1 mm	6 mm	32mm	1000N	0.12 kg
MPK044	586756	1 mm	6 mm	37mm	1000N	0.12 kg
MPK051	586757	1.25 mm	6 mm	37mm	1500N	0.14 kg
MPK058	586758	1.25 mm	6 mm	37mm	1500N	0.15 kg
MPK068	586759	1.25 mm	6 mm	40mm	1500N	0.16 kg
MPK078	586760	1.5 mm	6 mm	40mm	2000N	0.19 kg
MPK088	586761	1.5 mm	6 mm	40mm	2000N	0.2 kg
MPK098	586762	1.75 mm	6 mm	45mm	2500N	0.27 kg
MPK118	586763	1.75 mm	6 mm	50mm	2500N	0.3 kg
MPK138	586764	2 mm	6 mm	50mm	3000N	0.34 kg
MPK148	586765	2 mm	6 mm	50mm	3200N	0.4 kg
MPK160	586766	2 mm	6 mm	50mm	3200N	0.42 kg
MPK170	586767	2 mm	6 mm	50mm	3200N	0.42 kg
MPK201	586768	2.25 mm	6 mm	50mm	3600N	0.63 kg

ADDITIONAL PRODUCT DETAILS

Lining is EPDM rubber.

DIAGRAMS

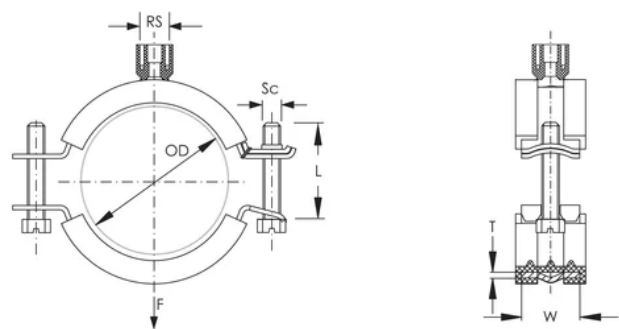

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER