



## NVENT CADDY MACROFIX PLUS NI EZ WITH EASY CLOSURE



### CERTIFICATIONS



### FEATURES

Contains easy closing mechanism

Plastic washers help prevent crushing the CPVC or plastic pipe and assure a floating fit

Flared edges and specially designed welding area help protect CPVC piping

Ideal for installations where space is limited and require services to be ran close to the attachment surface

Suitable for 3/4" - 2" (20 - 50 DN) steel sprinkler pipe

Eliminates the need to seismically brace when drops are kept within 6" (150 mm) of the attachment surface

Combo head bolt works with slotted, hex, or Phillips drivers

Conforms with Manufacturers Standardization Society (MSS) SP-58 (Type 12)

### SPECIFICATIONS

**Finish:** Electrogalvanized

**Material:** Steel

Table 1/2


Catalog Number	Article Number	E-Number	Pipe Size	NB/DN	Outer Diameter (OD)	Rod Size (RS)
MPZ020	595052	3532529	1/2"	15	20.0 - 21.3 mm	10
MPZ025	595053	3532531	3/4"	20	25.0 - 26.9 mm	10
MPZ032	595054	3532532	1"	25	32.0 - 33.7 mm	10
MPZ040	595056	3532533	1 1/4"	32	40.0 - 42.4 mm	10
MPZ050	595057	3532534	1 1/2"	40	48.3 - 50 mm	10
MPZ063	595059	3532535	2"	50	60.3 - 63 mm	10
MPZ075	595061	3532536	2 1/2"	65	75.0 - 76.1 mm	10

Table 2/2

Catalog Number	Article Number	E-Number	Width (W)	Thickness (T)	Static Load (F)	Certifications
MPZ020	595052	3532529	30 mm	1.5 mm	1125N	AON Fire Protection, BB019, pipe hangers
MPZ025	595053	3532531	30 mm	1.5 mm	1125N	AON Fire Protection, Macrofix Plus NI EZ, FM Approved, Pipe Hanger Components
MPZ032	595054	3532532	30 mm	1.5 mm	1125N	AON Fire Protection, Macrofix Plus NI EZ, FM Approved, Pipe Hanger Components
MPZ040	595056	3532533	30 mm	1.5 mm	1125N	AON Fire Protection, Macrofix Plus NI EZ, FM Approved, Pipe Hanger Components
MPZ050	595057	3532534	30 mm	2 mm	1725N	AON Fire Protection, Macrofix Plus NI EZ, FM Approved, Pipe Hanger Components

Catalog Number	Article Number	E-Number	Width (W)	Thickness(T)	Static Load (F)	Certifications
MPZ063	595059	3532535	30 mm	2 mm	1725N	AON Fire Protection, Macrofix Plus NI EZ, FM Approved, Pipe Hanger Components
MPZ075	595061	3532536	30 mm	2 mm	1725N	

### DIAGRAMS

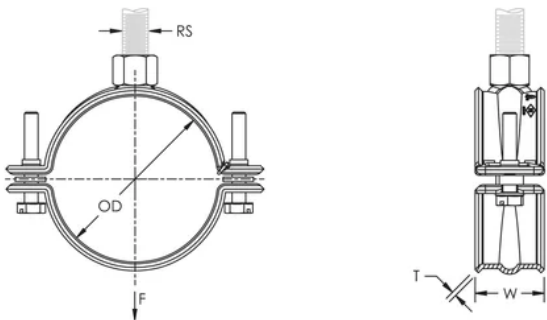

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

#### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

#### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

#### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com**   **CADDY**   **ERICO**   **HOFFMAN**   **RAYCHEM**   **SCHROFF**  
**TRACER**