



NVENT CADDY SPEED LINK SLK WITH THREADED STUD END



CERTIFICATIONS



FEATURES

Complete system includes wire, locking device and pre-assembled threaded stud end fitting

Attaches to structures with threaded anchors or devices with threaded hole

Connects directly to threaded devices in trapeze assemblies, light fixtures, HVAC assemblies or signage

SPECIFICATIONS

Static Load Safety Factor:	5:1
Finish:	Electrogalvanized
Material:	Steel;Polypropylene;Zinc Alloy
Complies With:	SMACNA HVAC-DCS

Table 1/3


Catalog Number	Article Number	E-Number	Wire Rope Diameter	Wire Rope Length	Rod Size (RS)	Screw Length (L)
SLK15L1SEM6	196564	1319660	1.5 mm	1m	6	25mm
SLK15L1SEM8	196565	3435534	1.5 mm	1m	8	45mm
SLK15L2SEM6	196566	1319661	1.5 mm	2m	6	25mm

Catalog Number	Article Number	E-Number	Wire Rope Diameter	Wire Rope Length	Rod Size(RS)	ScrewLength (L)
SLK15L2SEM8	196567	3435535	1.5 mm	2m	8	45mm
SLK15L3SEM6	196568	1319662	1.5 mm	3m	6	25mm
SLK15L3SEM8	196570		1.5 mm	3m	8	45mm
SLK2L2SEM8	196559	3435531	2 mm	2m	8	45mm
SLK2L3SEM8	196561	3435532	2 mm	3m	8	45mm
SLK2L5SEM6	196562		2 mm	5m	6	25mm
SLK2L5SEM8	196563	3435533	2 mm	5m	8	45mm

Table 2/3						
Catalog Number	Article Number	E-Number	Height (H)	Width (W)	Thickness (T)	Angle (a)
SLK15L1SEM6	196564	1319660	55 mm	19 mm	12.5 mm	90 ° Max
SLK15L1SEM8	196565	3435534	55 mm	19 mm	12.5 mm	90 ° Max
SLK15L2SEM6	196566	1319661	55 mm	19 mm	12.5 mm	90 ° Max
SLK15L2SEM8	196567	3435535	55 mm	19 mm	12.5 mm	90 ° Max
SLK15L3SEM6	196568	1319662	55 mm	19 mm	12.5 mm	90 ° Max
SLK15L3SEM8	196570		55 mm	19 mm	12.5 mm	90 ° Max
SLK2L2SEM8	196559	3435531	55 mm	19 mm	12.5 mm	90 ° Max
SLK2L3SEM8	196561	3435532	55 mm	19 mm	12.5 mm	90 ° Max
SLK2L5SEM6	196562		55 mm	19 mm	12.5 mm	90 ° Max
SLK2L5SEM8	196563	3435533	55 mm	19 mm	12.5 mm	90 ° Max

Table 3/3			
Catalog Number	Article Number	E-Number	Static Load (F)
SLK15L1SEM6	196564	1319660	195N
SLK15L1SEM8	196565	3435534	195N
SLK15L2SEM6	196566	1319661	195N
SLK15L2SEM8	196567	3435535	195N
SLK15L3SEM6	196568	1319662	195N
SLK15L3SEM8	196570		195N
SLK2L2SEM8	196559	3435531	440N
SLK2L3SEM8	196561	3435532	440N
SLK2L5SEM6	196562		440N
SLK2L5SEM8	196563	3435533	440N

DIAGRAMS

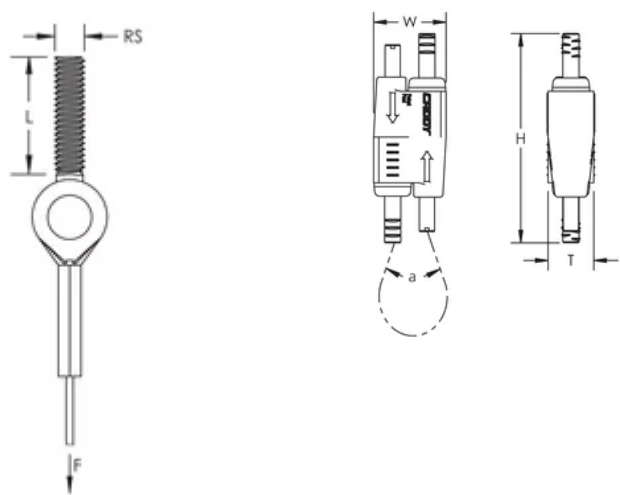

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER