



# NVENT CADDY SPEED LINK SLK WITH TOGGLE



## CERTIFICATIONS



## FEATURES

- Complete system includes wire, locking device and pre-assembled toggle end fitting
- Attaches to clearance holes in a variety of structures or hanging devices
- Ideal for supporting lighting fixtures
- Also available in Y-toggle configuration

## SPECIFICATIONS

<b>Wire Rope Diameter:</b>	1.5 mm
<b>Static Load Safety Factor:</b>	5:1
<b>Finish:</b>	Electrogalvanized
<b>Material:</b>	Steel;Zinc Alloy;Polypropylene
<b>Complies With:</b>	SMACNA HVAC-DCS

Table 1/2						
Catalog Number	Article Number	E-Number	Wire Rope Length	A	B	Static Load (F)
SLK15L10T	196526	1342892	10m	39 mm	5 mm	195N

Catalog Number	Article Number	E-Number	Wire Rope Length	A	B	Static Load (F)
SLK15L1T	196521	1342887	1m	39 mm	5 mm	195N
SLK15L2T	196522	1305139	2m	39 mm	5 mm	195N
SLK15L2TR2	196644		2m	39 mm	5 mm	195N
SLK15L3T	196523	1342889	3m	39 mm	5 mm	195N
SLK15L5T	196524	1342890	5m	39 mm	5 mm	195N
SLK15L7T	196525	1342891	7m	39 mm	5 mm	195N

Table 2/2

Catalog Number	Article Number	E-Number	Packing Quantity
SLK15L10T	196526	1342892	1.0000
SLK15L1T	196521	1342887	1.0000
SLK15L2T	196522	1305139	1.0000
SLK15L2TR2	196644		2.0000
SLK15L3T	196523	1342889	1.0000
SLK15L5T	196524	1342890	1.0000
SLK15L7T	196525	1342891	1.0000


**Thickness (T):** 12.5 mm

**Width (W):** 19 mm

**Height (H):** 55 mm

**Angle (a):** 90 ° Max

## DIAGRAMS

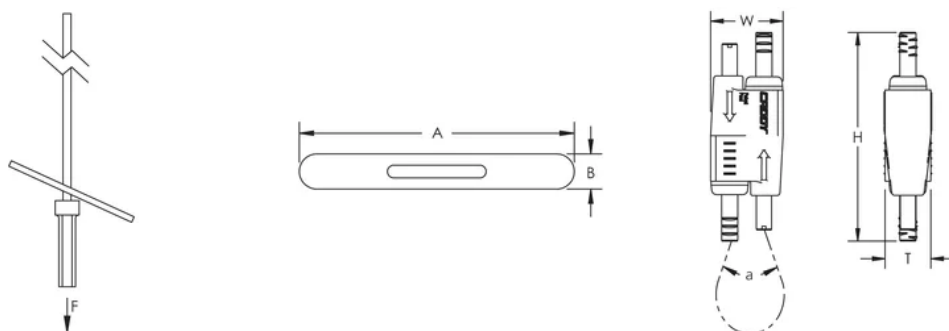

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**