



NVENT CADDY SPEED LINK Y-TOGGLE WITH EYELET EXTENSION



CERTIFICATIONS



FEATURES

Attaches to clearance holes in a variety of structures or hanging devices

Ideal for supporting lighting fixtures

Y-design provides improved stability

SPECIFICATIONS

Table 1/3

Catalog Number	Article Number	E-Number	Material	Finish	Static Load Safety Factor	Wire Rope Diameter
SLD15Y500	195960	1341314	Steel	Electrogalvanized	5:1	1.5 mm

Table 2/3

Catalog Number	Article Number	E-Number	Wire Rope "Y" Length (YL)	A	B	Static Load (F)
SLD15Y500	195960	1341314	0.5m	39 mm	5 mm	195N


Table 3/3

Catalog Number	Article Number	E-Number	Packing Quantity
SLD15Y500	195960	1341314	1.0000

ADDITIONAL PRODUCT DETAILS

nVent CADDY Speed Link locking device not included.

DIAGRAMS

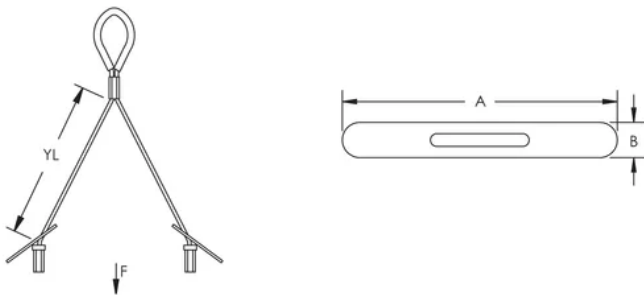

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER