


## FRONT PANEL, SHIELDED, BOTTOM HINGED

U-profile front panel bottom hinged for textile gasket.

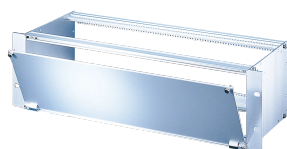

### CERTIFICATIONS



### FEATURES

U-profile front panel can be unhinged at 135° (not RatiopacPRO) opening angle

Enables mounting on horizontal rails

Shielded, U front panel with textile EMC gasket

Suitable for subracks (EuropacPRO) and cases (RatiopacPRO, PropacPRO, CompacPRO)

### SPECIFICATIONS

Table 1/3

Catalog Number	EMC Gasket Type	Treated Edges	Front Finish	Rear Finish	EMC Shielding	Rack Width
20848-599	Textile	No	Anodized	Conductive	No (Retrofittable)	42 HP
20848-600	Textile	No	Anodized	Conductive	No (Retrofittable)	63 HP
20848-601	Textile	No	Anodized	Conductive	No (Retrofittable)	84 HP
20848-602	Textile	No	Anodized	Conductive	No (Retrofittable)	42 HP

Catalog Number	EMC Gasket Type	Treated Edges	Front Finish	Rear Finish	EMC Shielding	Rack Width
20848-603	Textile	No	Anodized	Conductive	No (Retrofittable)	63 HP
20848-604	Textile	No	Anodized	Conductive	No (Retrofittable)	84 HP
20848-605	Textile	No	Anodized	Conductive	No (Retrofittable)	42 HP
20848-606	Textile	No	Anodized	Conductive	No (Retrofittable)	63 HP
20848-607	Textile	No	Anodized	Conductive	No (Retrofittable)	84 HP
20848-608	Textile	No	Anodized	Conductive	No (Retrofittable)	28 HP
20848-696	Textile	No	Anodized	Conductive	No (Retrofittable)	28 HP

Table 2/3						
Catalog Number	Package Quantity	Height	Product Type	Type	Rack Height	Width
20848-599	1	128.4 mm	Front Panel	Front Panel without Handle	3 U	213 mm
20848-600	1	128.4 mm	Front Panel	Front Panel without Handle	3 U	319.7 mm
20848-601	1	128.4 mm	Front Panel	Front Panel without Handle	3 U	426.4 mm
20848-602	1	261.8 mm	Front Panel	Front Panel without Handle	6 U	213 mm
20848-603	1	261.8 mm	Front Panel	Front Panel without Handle	6 U	319.7 mm
20848-604	1	261.8 mm	Front Panel	Front Panel without Handle	6 U	426.4 mm
20848-605	1	172.9 mm	Front Panel	Front Panel without Handle	4 U	213 mm
20848-606	1	172.9 mm	Front Panel	Front Panel without Handle	4 U	319.7 mm
20848-607	1	172.9 mm	Front Panel	Front Panel without Handle	4 U	426.4 mm
20848-608	1	128.4 mm	Front Panel	Front Panel without Handle	3 U	141.9 mm
20848-696	1	261.8 mm	Front Panel	Front Panel without Handle	6 U	141.9 mm

Table 3/3

Catalog Number	Complies With	Mounting	Material
20848-599	IEC 60297-3-101, IEEE 1101.1/10	Hinged, Bottom	Aluminum
20848-600	IEC 60297-3-101, IEEE 1101.1/10	Hinged, Bottom	Aluminum
20848-601	IEC 60297-3-101, IEEE 1101.1/10	Hinged, Bottom	Aluminum
20848-602	IEC 60297-3-101, IEEE 1101.1/10	Hinged, Bottom	Aluminum
20848-603	IEC 60297-3-101, IEEE 1101.1/10	Hinged, Bottom	Aluminum
20848-604	IEC 60297-3-101, IEEE 1101.1/10	Hinged, Bottom	Aluminum
20848-605	IEC 60297-3-101, IEEE 1101.1/10	Hinged, Bottom	Aluminum
20848-606	IEC 60297-3-101, IEEE 1101.1/10	Hinged, Bottom	Aluminum
20848-607	IEC 60297-3-101, IEEE 1101.1/10	Hinged, Bottom	Aluminum
20848-608	IEC 60297-3-101, IEEE 1101.1/10	Hinged, Bottom	Aluminum
20848-696	IEC 60297-3-101, IEEE 1101.1/10	Hinged, Bottom	Aluminum

## ADDITIONAL PRODUCT DETAILS

Front panel can be removed in opened position (> 135°).

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**