

BRANCH LINE RESTRAINT STRUCTURE ATTACHMENT TO WOOD/CONCRETE



CERTIFICATIONS



FEATURES

Swivel barrel nut accepts 3/8" or 1/2" (M10 or M12) threaded rod

Attaches to wood or concrete where cracked concrete approval is not needed

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel

Table 1/2

| Catalog Number | Article Number | Length (L) | Rod Size (RS) | Screw Diameter (Sc) | Height (H) | Screw Length (L) |
|----------------|----------------|------------|---------------|---------------------|------------|------------------|
| CSBBRS2EG | | 40.4mm | 0.375, 0.5 | 0.25in | 28.2mm | 44.5mm |
| CSBBRS2MEG | 402240 | 40.4mm | 10, 12 | 0.25in | 28.2mm | 44.5mm |

Table 2/2


| Catalog Number | Article Number | Width (W) | Drill Bit Diameter |
|----------------|----------------|-----------|--------------------|
| CSBBRS2EG | | 26.9mm | 5mm |

| Catalog Number | Article Number | Width (W) | Drill Bit Diameter |
|----------------|----------------|-----------|--------------------|
| CSBBRS2MEG | 402240 | 26.9mm | 5mm |

ADDITIONAL PRODUCT DETAILS

Branch line structural attachments are for restraint only and not for the hanging of fire sprinkler piping.

DIAGRAMS

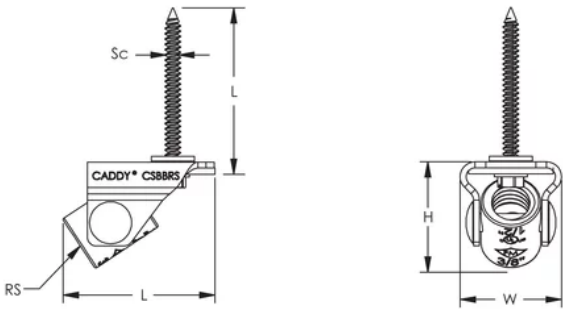

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:
nVent.com

CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER