



# PIN DRIVEN ANGLE BRACKET



## CERTIFICATIONS



## FEATURES

- Longer leg angle bracket for tool clearance
- Designed to fit a variety of pin drivers
- Improved for easier installation with pin drivers
- Preassembly options available for rod, wire, strap and cable applications

## SPECIFICATIONS

- Finish:** Pregalvanized
- Material:** Steel

Table 1/2						
Catalog Number	Hole Size 1 (HS1)	Hole Size 2 (HS2)	Height (H)	Length (L)	Width (W)	A
AFAB3	4.8 mm	7.1 mm	50.8 mm	44.2 mm	28.6 mm	7.1 mm
AFAB4	7.1 mm	7.1 mm	50.8 mm	44.2 mm	28.6 mm	7.1 mm
AFAB6	10.2 mm	7.1 mm	50.8 mm	44.2 mm	28.6 mm	7.1 mm

Table 2/2


Catalog Number	B	Static Load (F)
AFAB3	16.9 mm	700N
AFAB4	16.9 mm	1550N
AFAB6	16.9 mm	1550N

## ADDITIONAL PRODUCT DETAILS

Load limits apply to nVent CADDY Fasteners only.

Pin must be evaluated separately.

## DIAGRAMS

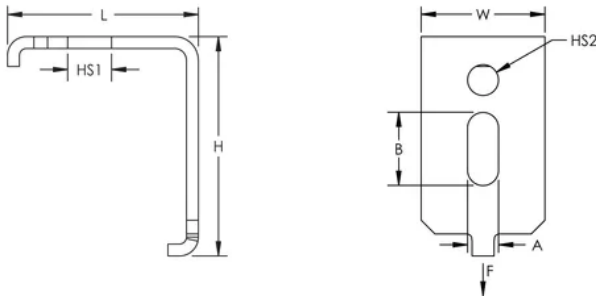

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**