


DISCONNECTING LINK

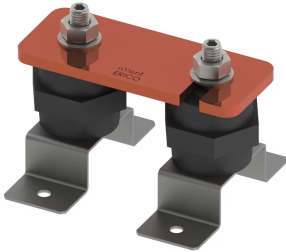

FEATURES

- Allows for quick and easy disconnection of the earthing system to facilitate testing of the earth in isolation
- High conductivity, hard drawn, electrolytic tough pitch copper per EN 13601
- Includes halogen-free polyamide insulators, stainless steel (EN 1.4401) hardware and mounting brackets

SPECIFICATIONS

- Material:** Copper
- Complies With:** IEC® EN 62561-1:2017 Class H

Table 1/2

Catalog Number	Finish	Width 1 (W1)	Width 2 (W2)	Height (H)	Thickness (T)	Length (L)
DLINKC	Bare	100mm	50mm	90mm	6mm	125mm
DLINKT	Tinned	100mm	50mm	90mm	6mm	125mm


Table 2/2

Catalog Number	Thread Size (TS)	Unit Weight
DLINKC	M10	0.77kg
DLINKT	M10	0.77kg

ADDITIONAL PRODUCT DETAILS

Tinned finish is 8 microns according to ASTM B545 Service Class "C" for corrosive environments.

DIAGRAMS

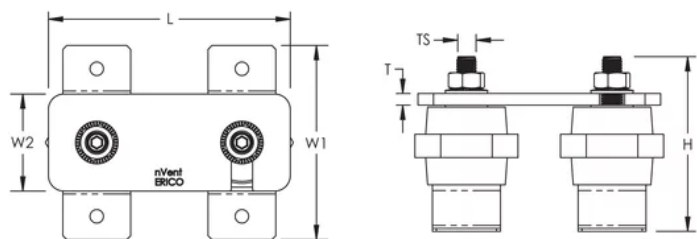

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER