


NON-INSULATED STRANDED CONDUCTOR

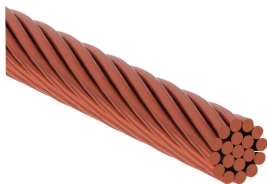

FEATURES

- Stranded pure electrolytic copper cable conductors for a variety of applications
- Stranded grounded conductor cut into standard lengths for easy field installation


SPECIFICATIONS

Table 1/1				
Catalog Number	Length (L)	Number of Wires	Wire Diameter	Unit Weight
A800A09F65	19.812 m	19	2.13 mm	12.100 kg
A800A22F100	30.500 m	19	2.69 mm	30 kg

ADDITIONAL PRODUCT DETAILS

Outer diameter dimensions are approximate.

DIAGRAMS

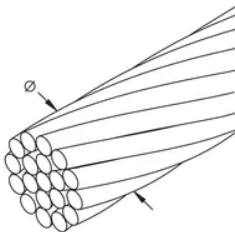

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER