



109 SIDE MOUNT STRAP FOR CPVC PIPE



CERTIFICATIONS



FEATURES

- Includes flared edges to protect piping
- Rated for use with CPVC fire sprinkler pipe
- Includes mounting screws

SPECIFICATIONS

- Finish:** Pregalvanized
- Material:** Steel

Table 1/2


Catalog Number	Article Number	Pipe Size	NB/DN	Outer Diameter (OD)	Hole Size (HS)	A
1090075EG	597827	3/4"	20	26.9 mm	5.8 mm	58.7 mm
1090100EG	597828	1"	25	33.7 mm	5.8 mm	66.7 mm
1090125EG	597829	1 1/4"	32	42.2 mm	5.8 mm	74.6 mm
1090150EG	597831	1 1/2"	40	48.3 mm	5.8 mm	81 mm

Catalog Number	Article Number	Pipe Size	NB/DN	Outer Diameter (OD)	Hole Size (HS)	A
1090200EG	597832	2"	50	60.3 mm	5.8 mm	92.1 mm

Table 2/2

Catalog Number	Article Number	B	C	Hanger Spacing
1090075EG	597827	42.9 mm	30.2 mm	1.65 m Max
1090100EG	597828	49.2 mm	30.2 mm	1.8 m Max
1090125EG	597829	58.7 mm	30.2 mm	1.95 m Max
1090150EG	597831	63.5 mm	30.2 mm	2.1 m Max
1090200EG	597832	76.2 mm	30.2 mm	2.4 m Max

DIAGRAMS

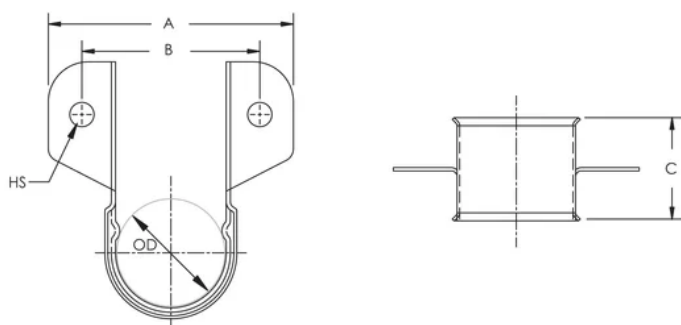

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER