


2000 U-CHANNEL

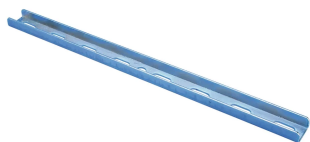

FEATURES

Light duty U-channel for use with 2000 series beam clamps

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel


Table 1/2

Catalog Number	Article Number	Length (L)	Height (H)	Width (W)	Thickness (T)	Hole Size (HS)
2002EG	570310	200 mm	12 mm	25 mm	2 mm	11 mm
2006EG	570350	400 mm	12 mm	25 mm	2 mm	11 mm

Table 2/2

Catalog Number	Article Number	X	A	B
2002EG	570310	8.5 x 25 mm	30.5 mm	25 mm
2006EG	570350	8.5 x 25 mm	30.5 mm	25 mm

 DIAGRAMS



WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER