



300 UNIVERSAL BEAM CLAMP



CERTIFICATIONS



FEATURES

Conforms with Federal Specification WW-H-171 (Type 23), Manufacturers Standardization Society (MSS) SP-58 (Type 19 and 23)

SPECIFICATIONS

Material: Cast Iron

Table 1/2						
Catalog Number	Finish	Rod Size (RS)	Flange Thickness (FT)	A	Torque (TQ)	Static Load 1 (F1)
3000037EG	Electrogalvanized	3/8"	19.05 mm Max	28.5 mm	7 N·m	2200N
3000037PL	Plain	3/8"	19.05 mm Max	28.58 mm	6.78 N·m	2200N
3000050EG	Electrogalvanized	1/2"	19.05 mm Max	28.57 mm	10.85 N·m	4200N
3000050PL	Plain	1/2"	19.05 mm Max	28.57 mm	10.85 N·m	4200N


Catalog Number	Finish	Rod Size(RS)	Flange Thickness (FT)	A	Torque (TQ)	Static Load1 (F1)
3000062EG	Electrogalvanized	5/8"	19.05 mm Max	28.57 mm	6.78 N·m	4200N
3000062PL	Plain	5/8"	19.05 mm Max	28.57 mm	6.78 N·m	4200N
3000075EG	Electrogalvanized	3/4"	19.05 mm Max	28.57 mm	6.78 N·m	4200N
3000075PL	Plain	3/4"	19.05 mm Max	28.57 mm	6.78 N·m	4200N
3000087EG	Electrogalvanized	7/8"	19.05 mm Max	28.57 mm	6.78 N·m	4200N
3000087PL	Plain	7/8"	19.05 mm Max	28.57 mm	6.78 N·m	4200N

Table 2/2			
Catalog Number	Static Load 2 (F2)	Packing Quantity	Certifications
3000037EG	1100N	1.0000	cUL, FM Approved, Pipe Hanger Components, UL
3000037PL	1100N	1.0000	cUL, FM Approved, Pipe Hanger Components, UL
3000050EG	3400N	1.0000	cUL, FM Approved, Pipe Hanger Components, UL
3000050PL	3400N	1.0000	cUL, FM Approved, Pipe Hanger Components, UL
3000062EG	3400N	1.0000	cUL, UL
3000062PL	3400N	1.0000	cUL, UL
3000075EG	3400N	1.0000	cUL, UL
3000075PL	3400N	1.0000	cUL, UL
3000087EG	3400N	1.0000	cUL, UL
3000087PL	3400N	1.0000	cUL, UL

ADDITIONAL PRODUCT DETAILS

Setscrew must be tightened and torqued onto the sloped side of the I-beam.

DIAGRAMS

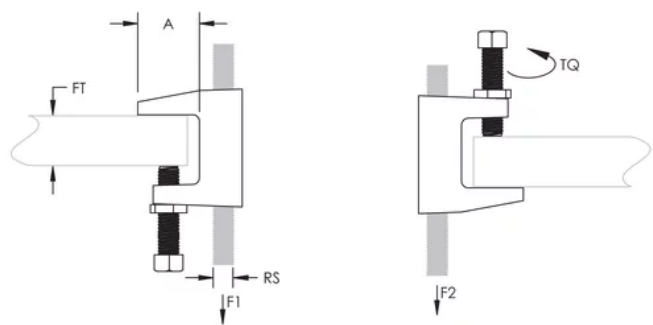

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER