



4G16 TWIST CLIP WITH STUD



CERTIFICATIONS



FEATURES

- Supports electrical fixtures from acoustical T-grid
- No tools required for installation
- Fast, easy and secure twist-on installation
- Nut sold separately

SPECIFICATIONS

Material: Spring Steel;Steel


Table 1/2

Catalog Number	Article Number	Finish	Color	Flange Thickness (FT)	T-Grid Size	Screw Diameter (Sc)
4G16M11	178600	nVent CADDY Armour	Gray	1.5 mm	24mm	6
4G16M11WH	178620	Painted	White	1.5 mm	24mm	6
4G16M16	171900	nVent CADDY Armour	Gray	1.5 mm	24mm	6

Catalog Number	Article Number	Finish	Color	Flange Thickness (FT)	T-Grid Size	Screw Diameter (Sc)
4G16M16WH	576940	Painted	White	1.5 mm	24mm	6
4G16M25	176880	nVent CADDY Armour	Gray	1.5 mm	24mm	6
4G16M7	178590	nVent CADDY Armour	Gray	1.5 mm	24mm	6

Table 2/2				
Catalog Number	Article Number	Screw Length (L)	Static Load (F)	Packing Quantity
4G16M11	178600	11mm	220N	1.0000
4G16M11WH	178620	11mm	220N	1.0000
4G16M16	171900	16mm	220N	1.0000
4G16M16WH	576940	16mm	220N	1.0000
4G16M25	176880	25mm	220N	1.0000
4G16M7	178590	7mm	220N	1.0000

DIAGRAMS

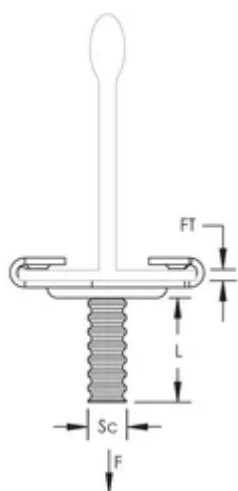

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER