




5000 BEAM CLAMP KIT

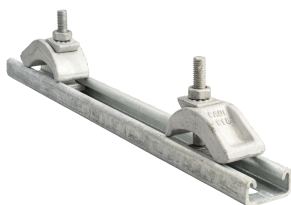

FEATURES

- C-Channel system
- Includes beam clamp and channel

SPECIFICATIONS

Finish: Hot-Dip Galvanized


Table 1/2						
Catalog Number	Article Number	Material	Length (L)	Channel Type	Rod Size (RS)	Flange Thickness (FT)
5300HD	335000	Steel	300 mm	E5	10	3 - 30 mm
5400HD	335010	Steel	400 mm	E5	10	3 - 30 mm
5400S4	335060	Stainless Steel 304 (EN 1.4301)	400 mm	E5	10	3 - 30 mm
5500HD	335020	Steel	500 mm	E5	10	3 - 30 mm
5600HD	335030	Steel	600 mm	E5	10	3 - 30 mm
5600S4	335080	Stainless Steel 304 (EN 1.4301)	600 mm	E5	10	3 - 30 mm
5800HD	335040	Steel	800 mm	E5	10	3 - 30 mm

Table 2/2		
Catalog Number	Article Number	Torque (TQ)

5300HD	335000	30 N·m
5400HD	335010	30 N·m
5400S4	335060	30 N·m
5500HD	335020	30 N·m
5600HD	335030	30 N·m
5600S4	335080	30 N·m
5800HD	335040	30 N·m

A	Static Load 1 F1	Static Load 2 F2
100 mm	3500 N	850 N
200 mm	1750 N	400 N
300 mm	1100 N	250 N
400 mm	800 N	200 N
500 mm	700 N	175 N
600 mm	500 N	125 N

DIAGRAMS

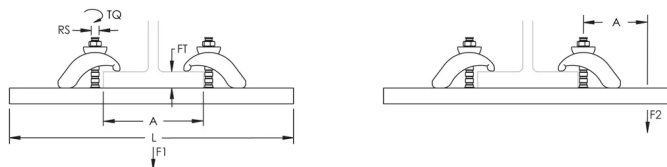

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER