



BC-M CONDUIT TO BEAM CLAMP



CERTIFICATIONS



FEATURES

- Easy installation to beam flanges
- Eliminates offset bending conduit
- Conduit clip rotates 360 degrees

SPECIFICATIONS


- Finish:** nVent CADDY Armour
- Material:** Spring Steel

Table 1/1

Catalog Number	Article Number	Outer Diameter (OD)	Flange Thickness (FT)	Torque (TQ)	Static Load (F)	Certifications
EBC6M	172580	14 - 18 mm	16 mm Max	3 N·m	450N	
EBC812M	160200	18 - 30 mm	16 mm Max	3 N·m	450N	ITB
EBC16M	172590	23.4 - 35 mm	16 mm Max	3 N·m	450N	ITB
EBC20M	172600	35 - 42 mm	16 mm Max	3 N·m	450N	ITB

Catalog Number	Article Number	Outer Diameter (OD)	Flange Thickness (FT)	Torque (TQ)	Static Load (F)	Certifications
EBC24M	172610	42 - 50 mm	16 mm Max	3 N·m	450N	ITB
EBC32M	172620	50 - 60 mm	16 mm Max	3 N·m	450N	ITB

DIAGRAMS

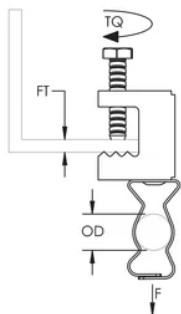

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER