

BEAM CLAMP WITH SWIVEL



CERTIFICATIONS



FEATURES

Swivel beam clamp

Suitable for mounting onto sloped steel structures

Includes M10 nut and washer

SPECIFICATIONS

Material: Steel


Table 1/1

Catalog Number	Article Number	Finish	Flange Thickness (FT)	Torque (TQ)	Angle 1 (a1)	Angle 2 (a2)
HB2	336030	Electrogalvanized	24 mm Max	6 N·m	45 ° Min	30 ° Max
HB2HD	336040	Hot-Dip Galvanized	24 mm Max	6 N·m	45 ° Min	30 ° Max

ADDITIONAL PRODUCT DETAILS

Setscrew must be tightened and torqued onto the sloped side of the I-beam.

DIAGRAMS

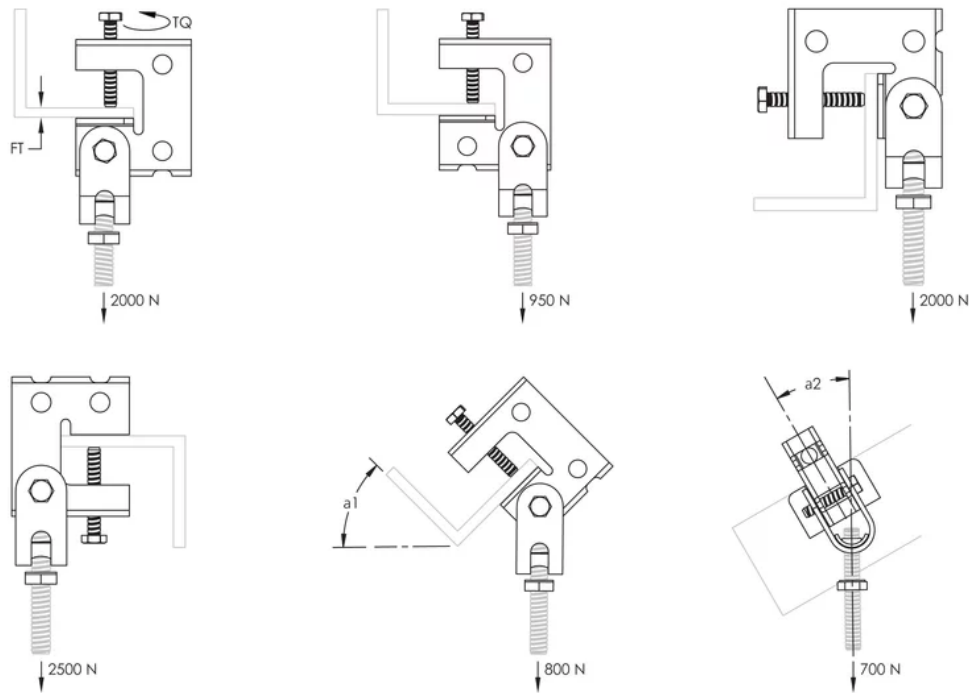

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America
+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe
Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe
Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC
Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER