

BSZ-SU CONCRETE SCREW



CERTIFICATIONS



FEATURES

Fire resistance class R30-R120 for design of anchorages under exposure to fire

ETA assessed for anchoring in cracked and non-cracked concrete

Approved for use in seismic design category C1 (all sizes)

Approved for use in seismic design category C2 (for Drill Bit Diameters 8 mm and greater)

Removable anchor is ideal for temporary fixings

Atlantis finish has superior corrosion protection (up to C3 environment according to EN ISO 9223 & 9224)

Atlantis finish is suitable for outdoor installation

SPECIFICATIONS

Material: Steel

Table 1/2

Catalog Number	Article Number	Finish	Drill Bit Diameter	Screw Length (L)	Embedment Depth	A
BSZSU06040ZL	402605	Atlantis	6mm	40mm	35 mm	5 mm
BSZSU08070ZL	402610	Atlantis	8mm	70mm	65 mm	5 mm


Catalog Number	Article Number	Finish	Drill Bit Diameter	ScrewLength (L)	Embedment Depth	A
BSZSU12110ZL	402625	Atlantis	12mm	110mm	105 mm	5 mm
BSZSU06040EG	402635	Electrogalvanize d	6mm	40mm	35 mm	5 mm
BSZSU08070EG	402645	Electrogalvanize d	8mm	70mm	65 mm	5 mm
BSZSU12110EG	402663	Electrogalvanize d	12mm	110mm	105 mm	5 mm
BSZSU06050ZL	402606	Atlantis	6mm	50mm	35 mm	15 mm
BSZSU10100ZL	402615	Atlantis	10mm	100mm	85 mm	15 mm
BSZSU06050EG	402640	Electrogalvanize d	6mm	50mm	35 mm	15 mm
BSZSU10100EG	402650	Electrogalvanize d	10mm	100mm	85 mm	15 mm
BSZSU10120ZL	402620	Atlantis	10mm	120mm	85 mm	35 mm
BSZSU10120EG	402658	Electrogalvanize d	10mm	120mm	85 mm	35 mm

Table 2/2

Catalog Number	Article Number	Torque (TQ)	Certifications
BSZSU06040ZL	402605	10 N·m	CE, 20-0046, CE, 20-0494
BSZSU08070ZL	402610	20 N·m	CE, 20-0046, VdS
BSZSU12110ZL	402625	50 N·m	CE, 20-0046, VdS
BSZSU06040EG	402635	10 N·m	CE, 20-0046, CE, 20-0494
BSZSU08070EG	402645	20 N·m	CE, 20-0046, VdS
BSZSU12110EG	402663	50 N·m	CE, 20-0046, VdS
BSZSU06050ZL	402606	10 N·m	CE, 20-0046, CE, 20-0494
BSZSU10100ZL	402615	30 N·m	CE, 20-0046, VdS
BSZSU06050EG	402640	10 N·m	CE, 20-0046, CE, 20-0494
BSZSU10100EG	402650	30 N·m	CE, 20-0046, VdS
BSZSU10120ZL	402620	30 N·m	CE, 20-0046, VdS
BSZSU10120EG	402658	30 N·m	CE, 20-0046, VdS

Characteristic Axial Loads from ETA-20/0046			
Part Number	Cracked Concrete C20/25	Non-Cracked Concrete C20/25	Standard Embedment Depth
BSZSU06040xx	1.81 kN	1.98 kN	35 mm
BSZSU06050xx	1.81 kN	1.98 kN	35 mm
BSZSU08070xx	5.88 kN	8.41 kN	65 mm
BSZSU10100xx	8.99 kN	12.85 kN	85 mm
BSZSU10120xx	8.99 kN	12.85 kN	85 mm
BSZSU12110xx	12.51 kN	17.87 kN	105 mm

DIAGRAMS

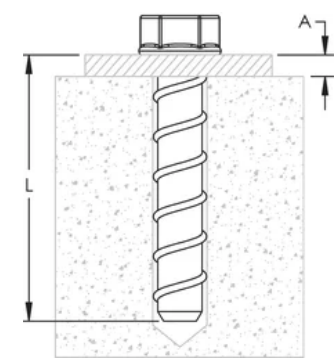

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America +1.800.753.9221 Option 1 – Customer Care Option 2 – Technical Support	Europe Netherlands: +31 800-0200135 France: +33 800 901 793	Europe Germany: 800 1890272 Other Countries: +31 13 5835404	APAC Shanghai: + 86 21 2412 1618/19 Sydney: +61 2 9751 8500
---	--	--	--