

## DUPLO NI DOUBLE PIPE CLAMP



### FEATURES

Fast installation of parallel pipes from a single anchor

Height adjustable

### SPECIFICATIONS

**Finish:** Electrogalvanized

**Material:** Steel


Table 1/2

Catalog Number	Article Number	Outer Diameter (OD)	Pipe Size	NB/DN	Width (W)	Thickness (T)
DUPLON15EG	596040	15 mm			20 mm	1.5 mm
DUPLON22EG	596041	22 mm	1/2"	15	20 mm	1.5 mm
DUPLON28EG	596042	28 mm	3/4"	20	20 mm	1.5 mm

Table 2/2

Catalog Number	Article Number	A	Screw Diameter (Sc)	Screw Length (L)
DUPLON15EG	596040	60 mm	6	16mm
DUPLON22EG	596041	60 mm	6	16mm
DUPLON28EG	596042	60 mm	6	16mm

DIAGRAMS

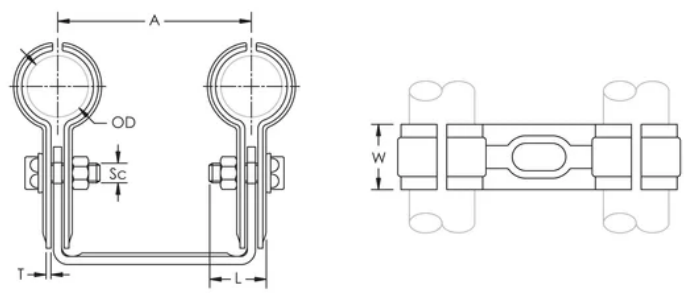

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**