



## HEAVY DUTY PIPE CLAMP PER DIN 3567, STEEL, HD, 26.9MM OD, 3/4" PIPE, 20 DN

### CATALOG NUMBER

**DIN027HD**



### FEATURES

For high static requirements in industrial construction

Suitable for fix point applications

Can be welded onto T-beam to form a sliding element

### PRODUCT ATTRIBUTES

Article Number: 400199

Material: Steel

Finish: Hot-Dip Galvanized

Outer Diameter (OD): 26.9 mm

Pipe Size: 3/4"

NB/DN: 20


Hole Size (HS): 11.5 mm

Width (W): 30 mm

Thickness (T): 5 mm

A: 64 mm

DIAGRAMS

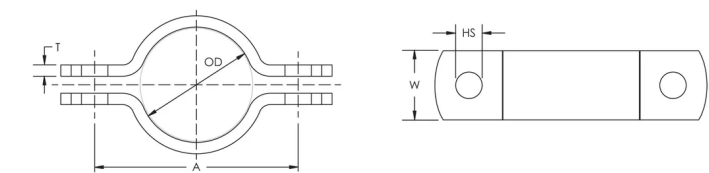

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**