



HD NI HEAVY DUTY PIPE CLAMP, FIRE/SPRINKLER, HD, 15–19 MM OD, 3/8" PIPE, 10 DN, M8, M10 ROD

CATALOG NUMBER

HDN019HD



FEATURES

Fillet welded connector nut has flats to accommodate spanners

Flared steel band also suitable for plastic pipe

Easy open flange for pipe sizes up to and including 4"

PRODUCT ATTRIBUTES

Article Number: 575001

Nut Included: Yes

Material: Steel

Finish: Hot-Dip Galvanized

Outer Diameter (OD): 15 - 19 mm

Pipe Size: 3/8"

NB/DN: 10


Rod Size (RS): 8;10

Width (W): 30 mm

Thickness (T): 2.5 mm

Static Load (F): 2000N

DIAGRAMS

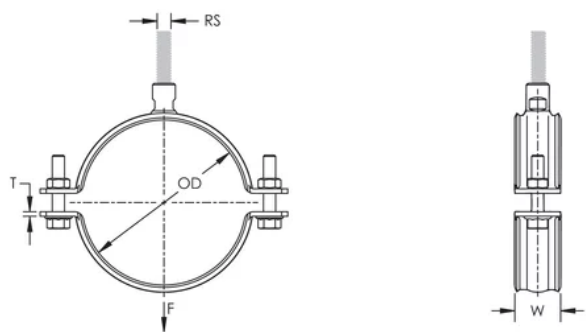

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America
+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe
Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe
Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC
Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER