



## HD NI HEAVY DUTY PIPE CLAMP, FIRE/SPRINKLER, HD, 20–24 MM OD, 1/2" PIPE, 15 DN, M8, M10 ROD

### CATALOG NUMBER

**HDN024HD**



### FEATURES

Fillet welded connector nut has flats to accommodate spanners

Flared steel band also suitable for plastic pipe

Easy open flange for pipe sizes up to and including 4"

### PRODUCT ATTRIBUTES

Article Number: 575002

Nut Included: Yes

Material: Steel

Finish: Hot-Dip Galvanized

Outer Diameter (OD): 20 - 24 mm

Pipe Size: 1/2"

NB/DN: 15


Rod Size (RS): 8;10

Width (W): 30 mm

Thickness (T): 2.5 mm

Static Load (F): 2000N

DIAGRAMS

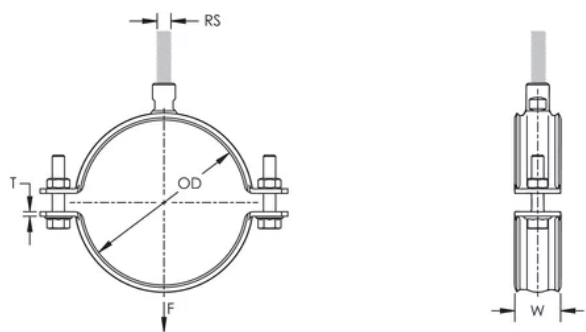

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**  
+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

**Europe**  
Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**  
Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**  
Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500