



HD NI HEAVY DUTY PIPE CLAMP, FIRE/SPRINKLER, HD, 140–146 MM OD, 5" PIPE, 125 DN, M12, M16 ROD

CATALOG NUMBER

HDN146HD



CERTIFICATIONS



FEATURES

Fillet welded connector nut has flats to accommodate spanners

Flared steel band also suitable for plastic pipe

Easy open flange for pipe sizes up to and including 4"

PRODUCT ATTRIBUTES

Article Number: 575020

Nut Included: Yes

Material: Steel

Finish: Hot-Dip Galvanized

Outer Diameter (OD): 140 - 146 mm

Pipe Size: 5"

NB/DN: 125


Rod Size (RS): 12;16

Width (W): 40 mm

Thickness (T): 4 mm

Static Load (F): 5000N

DIAGRAMS

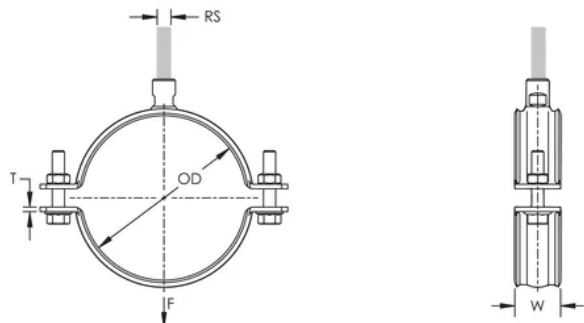

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER