



## NVENT CADDY MACROFIX NON-INSULATED M8/M10, 143–153 MM OD

### CATALOG NUMBER

**MFN153EG**



### CERTIFICATIONS



### FEATURES

Plastic washer prevents screws from falling out during installation

Combo head bolt works with slotted, hex, or Phillips drivers

Longer ears position the screw farther from the hanger, improving tool clearance when the screw is tightened

Combination nut can be attached to M8 or M10 threaded rod, simplifying material handling

Screw length has been optimized to accommodate an increased pipe range, reducing inventory

### PRODUCT ATTRIBUTES

Article Number: 586117

Material: Steel

Finish: Electrogalvanized


Outer Diameter (OD): 143 - 153 mm

Rod Size (RS): 8;10

Width (W): 25 mm

Thickness (T): 2 mm
Screw Diameter (Sc): 6
Screw Length (L): 27mm
Static Load (F): 3200N

DIAGRAMS

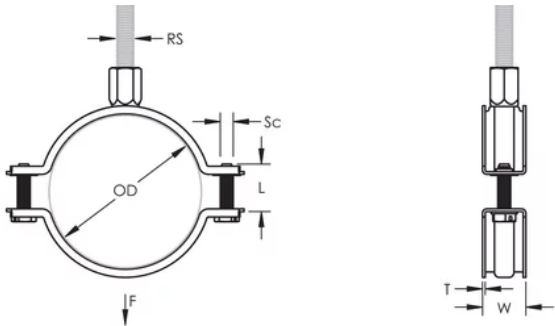

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

<b>North America</b> +1.800.753.9221 Option 1 – Customer Care Option 2 – Technical Support	<b>Europe</b> Netherlands: +31 800-0200135 France: +33 800 901 793	<b>Europe</b> Germany: 800 1890272 Other Countries: +31 13 5835404	<b>APAC</b> Shanghai: + 86 21 2412 1618/19 Sydney: +61 2 9751 8500
---	--	--	--