



## NVENT CADDY MACROFIX PLUS NON-INSULATED, 165–175 MM OD, M8, M10 ROD

### CATALOG NUMBER

**MFZ175**



### CERTIFICATIONS



### FEATURES

Increased opening angle easily accommodates all standard-sized pipes

Quick locking system prevents the hanger from accidentally opening when pipe is moved or adjusted

Quick locking system easily closes with one hand

Thread impression retains quick locking captive screw and prevents it from falling out during installation

Combo head bolt works with slotted, hex, or Phillips drivers

Longer ears position the screw farther from the hanger, improving tool clearance when the screw is tightened

Combination nut can be attached to M8 or M10 threaded rod, simplifying material handling

Screw length has been optimized to accommodate an increased pipe range, reducing inventory


### PRODUCT ATTRIBUTES

Article Number: 586819

Material: Steel

Finish: Electrogalvanized
Outer Diameter (OD): 165 - 175 mm
Rod Size (RS): 8;10
NB/DN: 150
Pipe Size: 6"
Width (W): 25 mm
Thickness (T): 2 mm
Screw Diameter (Sc): 6
Screw Length (L): 40mm
Static Load (F): 3200N

DIAGRAMS

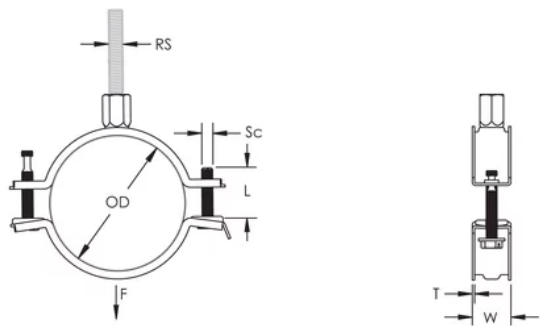

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

<b>North America</b> +1.800.753.9221 Option 1 – Customer Care Option 2 – Technical Support	<b>Europe</b> Netherlands: +31 800-0200135 France: +33 800 901 793	<b>Europe</b> Germany: 800 1890272 Other Countries: +31 13 5835404	<b>APAC</b> Shanghai: + 86 21 2412 1618/19 Sydney: +61 2 9751 8500
---	--	--	--