

## PX HEAVY DUTY PIPE CLAMP WITH EXTERNAL THREAD, S316, EPDM-SBR, 41–45 MM OD, 1 1/4" PIPE, 32 DN

### CATALOG NUMBER

**PXI045S6**



### FEATURES

Includes male/female combination nut

Category II noise reduction according to DIN EN ISO 3822-1

Compliant for sound insulation design according to DIN 4109

Reaction-to-fire classification is "E" in compliance with DIN EN 13501-1

### PRODUCT ATTRIBUTES

Article Number: 578310

Material: Stainless Steel 316 (EN 1.4401);EPDM-SBR Rubber

Temperature: -50 to 120 °C

Outer Diameter (OD): 41 - 45 mm

Pipe Size: 1 1/4"

NB/DN: 32

Rod Size (RS): 10

Gewinde (G): 1/2"

Width (W): 27 mm

Thickness (T): 2 mm

Screw Diameter (Sc): 6


Screw Length (L): 20mm

Static Load (F): 2500N

ADDITIONAL PRODUCT DETAILS

Lining is EPDM rubber.

DIAGRAMS

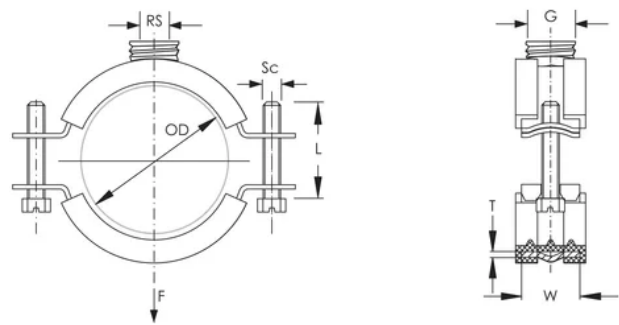

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**  
+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

**Europe**  
Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**  
Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**  
Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**