



PX NI HD PIPE CLAMP W/EXT. THREAD, S316, 246–252 MM OD, 3/4" THREAD, 38 MM

CATALOG NUMBER

PXN252S6



FEATURES

Includes male/female combination nut

Heavy duty

PRODUCT ATTRIBUTES

Article Number: 577800

Nut Included: Yes

Material: Stainless Steel 316 (EN 1.4401)

Outer Diameter (OD): 246 - 252 mm

Rod Size (RS): 12

Gewinde (G): 3/4"

Width (W): 38 mm


Thickness (T): 2.5 mm

Screw Diameter (Sc): 8

Screw Length (L): 30mm

Static Load (F): 3500N

DIAGRAMS

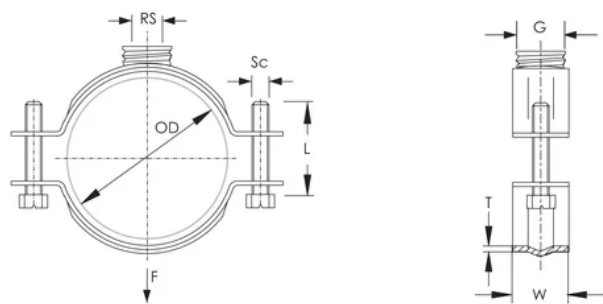

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America
+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe
Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe
Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC
Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER