



## INTERNAL STRUT BEAM CLAMP WITH BOLT



### FEATURES

U-shaped clip for clamping the back of strut channel to a beam

Hex bolt included

Requires installation in pairs

### SPECIFICATIONS

Table 1/2

Catalog Number	Article Number	Material	Finish	Flange Thickness (FT)	Width (W)	Screw Diameter (Sc)
ZT606HDEG	313270	Steel	Hot-Dip Galvanized, Electrogalvanized	28 mm Max	30 mm	10

Table 2/2


Catalog Number	Article Number	Static Load (F)
ZT606HDEG	313270	2900N

### ADDITIONAL PRODUCT DETAILS

Static Load is based on one pair of Strut Beam Clamps.

Include strut channel thickness when calculating flange thickness.

DIAGRAMS

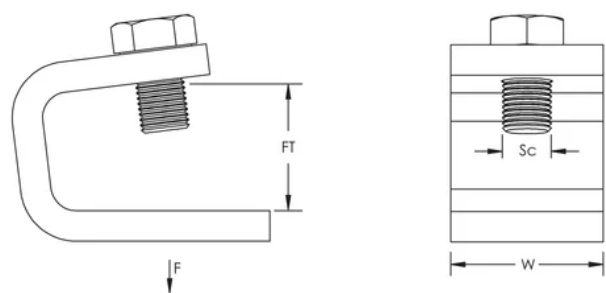

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**