

OVAL PIPE CLAMP WITH NUT



FEATURES

Designed to support pre-insulated twin tubes and integrated power cable for solar heat collectors

Shape of clamp provides a stable attachment to wall or ceiling

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel

Table 1/2


Catalog Number	Article Number	NB/DN	Rod Size (RS)	A	B	Width (W)
MXOVDN1012EG	401161	10, 12	8, 10	30 mm	69 mm	20 mm
MXOVDN1215EG	401244	12, 15	8, 10	43 mm	78 mm	20 mm
MXOVDN1618EG	401245	16, 18	8, 10	51 mm	88 mm	20 mm
MXOVDN20EG	401246	20	8, 10	58 mm	108 mm	20 mm
MXOVDN25EG	403800	25	8, 10	71 mm	124 mm	20 mm

Table 2/2

Catalog Number	Article Number	Thickness (T)	Screw Diameter (Sc)	Screw Length (L)
MXOVDN1012EG	401161	2 mm	6	20mm

Catalog Number	Article Number	Thickness (T)	Screw Diameter (Sc)	Screw Length (L)
MXOVDN1215EG	401244	2 mm	6	20mm
MXOVDN1618EG	401245	2 mm	6	20mm
MXOVDN20EG	401246	2 mm	6	20mm
MXOVDN25EG	403800	2 mm	6	20mm

DIAGRAMS

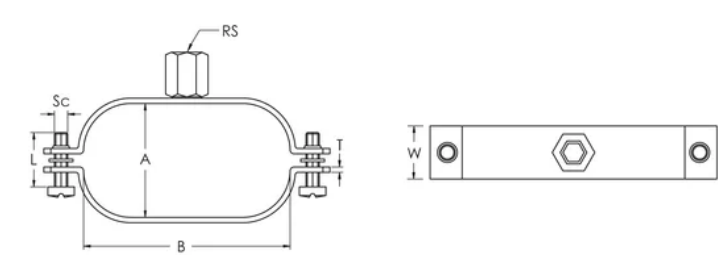

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com **CADDY ERICO HOFFMAN RAYCHEM SCHROFF**
TRACER