



PEMSA WIRE BASKET TRAY



The PEMS Wire Basket Tray is the backbone of PEMS Wire Basket Tray System. Highly engineered features help ensure a secure installation that complies with industry codes and standards for high-performance cables. Clever design allows the installer to maximize field efficiency with the Rejiband Rapide Integrated Splice.

CERTIFICATIONS



FEATURES

- Provides optimal support for high-performance low voltage and data cables
- Innovative Rejiband Rapide installation system
- IEC 61537 load rating and earthing compliant
- Responsive design and layout services, including seismic

SPECIFICATIONS

Color: Black

Table 1/2

Catalog Number	Article Number	Material	Finish	Length (L)	Height (H)	Width (W)
WBT35X60S4	821003	Stainless Steel 304 (EN 1.4301)		3000 mm	35 mm	60 mm
WBT35X60BA	821001	Carbon Steel	Powder Coated	3000 mm	35 mm	60 mm
WBT35X60EG	821000	Carbon Steel	Electrogalvanized	3000 mm	35 mm	60 mm

Catalog Number	Article Number	Material	Finish	Length (L)	Height (H)	Width (W)
WBT35X100BA	821011	Carbon Steel	Powder Coated	3000 mm	35 mm	100 mm
WBT35X100EG	821010	Carbon Steel	Electrogalvanized	3000 mm	35 mm	100 mm
WBT35X100S4	821013	Stainless Steel 304 (EN 1.4301)		3000 mm	35 mm	100 mm
WBT35X150BA	821021	Carbon Steel	Powder Coated	3000 mm	35 mm	150 mm
WBT35X150EG	821020	Carbon Steel	Electrogalvanized	3000 mm	35 mm	150 mm
WBT35X150S4	821023	Stainless Steel 304 (EN 1.4301)		3000 mm	35 mm	150 mm
WBT35X200BA	821031	Carbon Steel	Powder Coated	3000 mm	35 mm	200 mm
WBT35X200EG	821030	Carbon Steel	Electrogalvanized	3000 mm	35 mm	200 mm
WBT35X200S4	821033	Stainless Steel 304 (EN 1.4301)		3000 mm	35 mm	200 mm
WBT35X300BA	821041	Carbon Steel	Powder Coated	3000 mm	35 mm	300 mm
WBT35X300EG	821040	Carbon Steel	Electrogalvanized	3000 mm	35 mm	300 mm
WBT35X300S4	821043	Stainless Steel 304 (EN 1.4301)		3000 mm	35 mm	300 mm
WBT35X400BA	821051	Carbon Steel	Powder Coated	3000 mm	35 mm	400 mm
WBT35X400EG	821050	Carbon Steel	Electrogalvanized	3000 mm	35 mm	400 mm
WBT35X400S4	821053	Stainless Steel 304 (EN 1.4301)		3000 mm	35 mm	400 mm
WBT60X60BA	820001	Carbon Steel	Powder Coated	3000 mm	60 mm	60 mm
WBT60X60BG	820002	Carbon Steel	Electrogalvanized	3000 mm	60 mm	60 mm
WBT60X60EG	820000	Carbon Steel	Electrogalvanized	3000 mm	60 mm	60 mm
WBT60X60S4	820003	Stainless Steel 304 (EN 1.4301)		3000 mm	60 mm	60 mm
WBT60X100BA	820011	Carbon Steel	Powder Coated	3000 mm	60 mm	100 mm
WBT60X100BG	820012	Carbon Steel	Electrogalvanized	3000 mm	60 mm	100 mm
WBT60X100EG	820010	Carbon Steel	Electrogalvanized	3000 mm	60 mm	100 mm
WBT60X100S4	820013	Stainless Steel 304 (EN 1.4301)		3000 mm	60 mm	100 mm

Catalog Number	Article Number	Material	Finish	Length (L)	Height (H)	Width (W)
WBT60X150BA	820021	Carbon Steel	Powder Coated	3000 mm	60 mm	150 mm
WBT60X150BG	820022	Carbon Steel	Electrogalvanized	3000 mm	60 mm	150 mm
WBT60X150EG	820020	Carbon Steel	Electrogalvanized	3000 mm	60 mm	150 mm
WBT60X150S4	820023	Stainless Steel 304 (EN 1.4301)		3000 mm	60 mm	150 mm
WBT60X200BA	820031	Carbon Steel	Powder Coated	3000 mm	60 mm	200 mm
WBT60X200BG	820032	Carbon Steel	Electrogalvanized	3000 mm	60 mm	200 mm
WBT60X200EG	820030	Carbon Steel	Electrogalvanized	3000 mm	60 mm	200 mm
WBT60X200S4	820033	Stainless Steel 304 (EN 1.4301)		3000 mm	60 mm	200 mm
WBT60X300BA	820041	Carbon Steel	Powder Coated	3000 mm	60 mm	300 mm
WBT60X300BG	820042	Carbon Steel	Electrogalvanized	3000 mm	60 mm	300 mm
WBT60X300EG	820040	Carbon Steel	Electrogalvanized	3000 mm	60 mm	300 mm
WBT60X300S4	820043	Stainless Steel 304 (EN 1.4301)		3000 mm	60 mm	300 mm
WBT60X400BA	820051	Carbon Steel	Powder Coated	3000 mm	60 mm	400 mm
WBT60X400BG	820052	Carbon Steel	Electrogalvanized	3000 mm	60 mm	400 mm
WBT60X400EG	820050	Carbon Steel	Electrogalvanized	3000 mm	60 mm	400 mm
WBT60X400S4	820053	Stainless Steel 304 (EN 1.4301)		3000 mm	60 mm	400 mm
WBT60X450BA	820081	Carbon Steel	Powder Coated	3000 mm	60 mm	450 mm
WBT60X450BG	820082	Carbon Steel	Electrogalvanized	3000 mm	60 mm	450 mm
WBT60X450EG	820080	Carbon Steel	Electrogalvanized	3000 mm	60 mm	450 mm
WBT60X450S4	820083	Stainless Steel 304 (EN 1.4301)		3000 mm	60 mm	450 mm
WBT60X500BA	820061	Carbon Steel	Powder Coated	3000 mm	60 mm	500 mm
WBT60X500BG	820062	Carbon Steel	Electrogalvanized	3000 mm	60 mm	500 mm
WBT60X500EG	820060	Carbon Steel	Electrogalvanized	3000 mm	60 mm	500 mm

Catalog Number	Article Number	Material	Finish	Length (L)	Height (H)	Width (W)
WBT60X500S4	820063	Stainless Steel 304 (EN 1.4301)		3000 mm	60 mm	500 mm
WBT60X600BA	820075	Carbon Steel	Powder Coated	3000 mm	60 mm	600 mm
WBT60X600BG	820076	Carbon Steel	Electrogalvanized	3000 mm	60 mm	600 mm
WBT60X600EG	820074	Carbon Steel	Electrogalvanized	3000 mm	60 mm	600 mm
WBT60X600S4	820077	Stainless Steel 304 (EN 1.4301)		3000 mm	60 mm	600 mm
WBT100X100BA	823011	Carbon Steel	Powder Coated	3000 mm	100 mm	100 mm
WBT100X100BG	823012	Carbon Steel	Electrogalvanized	3000 mm	100 mm	100 mm
WBT100X100EG	823010	Carbon Steel	Electrogalvanized	3000 mm	100 mm	100 mm
WBT100X100S4	823013	Stainless Steel 304 (EN 1.4301)		3000 mm	100 mm	100 mm
WBT100X150BA	823021	Carbon Steel	Powder Coated	3000 mm	100 mm	150 mm
WBT100X150BG	823022	Carbon Steel	Electrogalvanized	3000 mm	100 mm	150 mm
WBT100X150EG	823020	Carbon Steel	Electrogalvanized	3000 mm	100 mm	150 mm
WBT100X150S4	823023	Stainless Steel 304 (EN 1.4301)		3000 mm	100 mm	150 mm
WBT100X200BA	823031	Carbon Steel	Powder Coated	3000 mm	100 mm	200 mm
WBT100X200BG	823032	Carbon Steel	Electrogalvanized	3000 mm	100 mm	200 mm
WBT100X200EG	823030	Carbon Steel	Electrogalvanized	3000 mm	100 mm	200 mm
WBT100X200S4	823033	Stainless Steel 304 (EN 1.4301)		3000 mm	100 mm	200 mm
WBT100X300BA	823041	Carbon Steel	Powder Coated	3000 mm	100 mm	300 mm
WBT100X300BG	823042	Carbon Steel	Electrogalvanized	3000 mm	100 mm	300 mm
WBT100X300EG	823040	Carbon Steel	Electrogalvanized	3000 mm	100 mm	300 mm
WBT100X300S4	823043	Stainless Steel 304 (EN 1.4301)		3000 mm	100 mm	300 mm
WBT100X400BA	823051	Carbon Steel	Powder Coated	3000 mm	100 mm	400 mm
WBT100X400BG	823052	Carbon Steel	Electrogalvanized	3000 mm	100 mm	400 mm

Catalog Number	Article Number	Material	Finish	Length (L)	Height (H)	Width (W)
WBT100X400EG	823050	Carbon Steel	Electrogalvanized	3000 mm	100 mm	400 mm
WBT100X400S4	823053	Stainless Steel 304 (EN 1.4301)		3000 mm	100 mm	400 mm
WBT100X450BA	823081	Carbon Steel	Powder Coated	3000 mm	100 mm	450 mm
WBT100X450BG	823082	Carbon Steel	Electrogalvanized	3000 mm	100 mm	450 mm
WBT100X450EG	823080	Carbon Steel	Electrogalvanized	3000 mm	100 mm	450 mm
WBT100X450S4	823083	Stainless Steel 304 (EN 1.4301)		3000 mm	100 mm	450 mm
WBT100X500BA	823061	Carbon Steel	Powder Coated	3000 mm	100 mm	500 mm
WBT100X500BG	823062	Carbon Steel	Electrogalvanized	3000 mm	100 mm	500 mm
WBT100X500EG	823060	Carbon Steel	Electrogalvanized	3000 mm	100 mm	500 mm
WBT100X500S4	823063	Stainless Steel 304 (EN 1.4301)		3000 mm	100 mm	500 mm
WBT100X600BA	823071	Carbon Steel	Powder Coated	3000 mm	100 mm	600 mm
WBT100X600BG	823072	Carbon Steel	Electrogalvanized	3000 mm	100 mm	600 mm
WBT100X600EG	823070	Carbon Steel	Electrogalvanized	3000 mm	100 mm	600 mm
WBT100X600S4	823073	Stainless Steel 304 (EN 1.4301)		3000 mm	100 mm	600 mm
WBT150X200BA	825031	Carbon Steel	Powder Coated	3000 mm	150 mm	200 mm
WBT150X200BG	825032	Carbon Steel	Electrogalvanized	3000 mm	150 mm	200 mm
WBT150X200EG	825030	Carbon Steel	Electrogalvanized	3000 mm	150 mm	200 mm
WBT150X200S4	825033	Stainless Steel 304 (EN 1.4301)		3000 mm	150 mm	200 mm
WBT150X300BA	825041	Carbon Steel	Powder Coated	3000 mm	150 mm	300 mm
WBT150X300BG	825042	Carbon Steel	Electrogalvanized	3000 mm	150 mm	300 mm
WBT150X300EG	825040	Carbon Steel	Electrogalvanized	3000 mm	150 mm	300 mm
WBT150X300S4	825043	Stainless Steel 304 (EN 1.4301)		3000 mm	150 mm	300 mm
WBT150X400BA	825051	Carbon Steel	Powder Coated	3000 mm	150 mm	400 mm

Catalog Number	Article Number	Material	Finish	Length (L)	Height (H)	Width (W)
WBT150X400BG	825052	Carbon Steel	Electrogalvanized	3000 mm	150 mm	400 mm
WBT150X400EG	825050	Carbon Steel	Electrogalvanized	3000 mm	150 mm	400 mm
WBT150X400S4	825053	Stainless Steel 304 (EN 1.4301)		3000 mm	150 mm	400 mm
WBT150X450BA	825081	Carbon Steel	Powder Coated	3000 mm	150 mm	450 mm
WBT150X450BG	825082	Carbon Steel	Electrogalvanized	3000 mm	150 mm	450 mm
WBT150X450EG	825080	Carbon Steel	Electrogalvanized	3000 mm	150 mm	450 mm
WBT150X450S4	825083	Stainless Steel 304 (EN 1.4301)		3000 mm	150 mm	450 mm
WBT150X500BA	825061	Carbon Steel	Powder Coated	3000 mm	150 mm	500 mm
WBT150X500BG	825062	Carbon Steel	Electrogalvanized	3000 mm	150 mm	500 mm
WBT150X500EG	825060	Carbon Steel	Electrogalvanized	3000 mm	150 mm	500 mm
WBT150X500S4	825063	Stainless Steel 304 (EN 1.4301)		3000 mm	150 mm	500 mm
WBT150X600BA	825071	Carbon Steel	Powder Coated	3000 mm	150 mm	600 mm
WBT150X600BG	825072	Carbon Steel	Electrogalvanized	3000 mm	150 mm	600 mm
WBT150X600EG	825070	Carbon Steel	Electrogalvanized	3000 mm	150 mm	600 mm
WBT150X600S4	825073	Stainless Steel 304 (EN 1.4301)		3000 mm	150 mm	600 mm
WBT150X900BA	825091	Carbon Steel	Powder Coated	3000 mm	150 mm	900 mm
WBT150X900BG	825092	Carbon Steel	Electrogalvanized	3000 mm	150 mm	900 mm
WBT150X900EG	825090	Carbon Steel	Electrogalvanized	3000 mm	150 mm	900 mm
WBT150X900S4	825093	Stainless Steel 304 (EN 1.4301)		3000 mm	150 mm	900 mm

Table 2/2

Catalog Number	Article Number	Unit Weight	Certifications
WBT35X60S4	821003	1.19 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT35X60BA	821001	1.2 kg	

Catalog Number	Article Number	Unit Weight	Certifications
WBT35X60EG	821000	1.2 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT35X100BA	821011	1.62 kg	
WBT35X100EG	821010	1.62 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT35X100S4	821013	1.61 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT35X150BA	821021	1.76 kg	
WBT35X150EG	821020	1.76 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT35X150S4	821023	2.12 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT35X200BA	821031	2.5 kg	
WBT35X200EG	821030	2.5 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT35X200S4	821033	3.04 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT35X300BA	821041	3.42 kg	
WBT35X300EG	821040	3.42 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT35X300S4	821043	4.13 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT35X400BA	821051	4.29 kg	
WBT35X400EG	821050	4.29 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT35X400S4	821053	5.22 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X60BA	820001	2.32 kg	
WBT60X60BG	820002	2.32 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X60EG	820000	2.32 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT

Catalog Number	Article Number	Unit Weight	Certifications
WBT60X60S4	820003	2.32 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X100BA	820011	2.43 kg	
WBT60X100BG	820012	2.43 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X100EG	820010	2.43 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X100S4	820013	2.43 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X150BA	820021	2.6 kg	
WBT60X150BG	820022	2.6 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X150EG	820020	2.6 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X150S4	820023	2.6 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X200BA	820031	3.33 kg	
WBT60X200BG	820032	3.33 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X200EG	820030	3.33 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X200S4	820033	3.33 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X300BA	820041	5.13 kg	

Catalog Number	Article Number	Unit Weight	Certifications
WBT60X300BG	820042	5.13 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X300EG	820040	5.13 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X300S4	820043	5.13 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X400BA	820051	6.21 kg	
WBT60X400BG	820052	6.21 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X400EG	820050	6.21 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X400S4	820053	6.21 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X450BA	820081	6.39 kg	
WBT60X450BG	820082	6.39 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X450EG	820080	6.39 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X450S4	820083	6.39 kg	
WBT60X500BA	820061	7.35 kg	
WBT60X500BG	820062	7.35 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X500EG	820060	7.35 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X500S4	820063	7.35 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X600BA	820075	8.43 kg	


Catalog Number	Article Number	Unit Weight	Certifications
WBT60X600BG	820076	8.43 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X600EG	820074	8.43 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X600S4	820077	8.43 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT100X100BA	823011	3.27 kg	
WBT100X100BG	823012	3.27 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT100X100EG	823010	3.27 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT100X100S4	823013	3.27 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT100X150BA	823021	3.45 kg	
WBT100X150BG	823022	3.45 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT100X150EG	823020	3.45 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT100X150S4	823023	3.45 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT100X200BA	823031	4.14 kg	
WBT100X200BG	823032	4.14 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT100X200EG	823030	4.14 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT

Catalog Number	Article Number	Unit Weight	Certifications
WBT100X200S4	823033	4.14 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT100X300BA	823041	6.15 kg	
WBT100X300BG	823042	6.15 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT100X300EG	823040	6.15 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT100X300S4	823043	6.15 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT100X400BA	823051	7.23 kg	
WBT100X400BG	823052	7.23 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT100X400EG	823050	7.23 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT100X400S4	823053	7.23 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT100X450BA	823081	7.44 kg	
WBT100X450BG	823082	7.44 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT100X450EG	823080	7.44 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT100X450S4	823083	7.44 kg	
WBT100X500BA	823061	8.34 kg	
WBT100X500BG	823062	8.34 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT

Catalog Number	Article Number	Unit Weight	Certifications
WBT100X500EG	823060	8.34 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT100X500S4	823063	8.34 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT100X600BA	823071	9.42 kg	
WBT100X600BG	823072	9.42 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT100X600EG	823070	9.42 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT100X600S4	823073	9.42 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X200BA	825031	6.01 kg	
WBT150X200BG	825032	6.01 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X200EG	825030	6.01 kg	CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X200S4	825033	6.01 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X300BA	825041	7.29 kg	
WBT150X300BG	825042	7.29 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X300EG	825040	7.29 kg	CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X300S4	825043	7.29 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X400BA	825051	8.47 kg	
WBT150X400BG	825052	8.47 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X400EG	825050	8.47 kg	CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X400S4	825053	8.47 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X450BA	825081	8.68 kg	

Catalog Number	Article Number	Unit Weight	Certifications
WBT150X450BG	825082	8.68 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X450EG	825080	8.68 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X450S4	825083	8.68 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X500BA	825061	9.7 kg	
WBT150X500BG	825062	9.7 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X500EG	825060	9.7 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X500S4	825063	9.7 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X600BA	825071	10.65 kg	
WBT150X600BG	825072	10.65 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X600EG	825070	10.65 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X600S4	825073	10.65 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X900BA	825091	15.98 kg	
WBT150X900BG	825092	15.98 kg	
WBT150X900EG	825090	15.98 kg	
WBT150X900S4	825093	15.98 kg	

DIAGRAMS

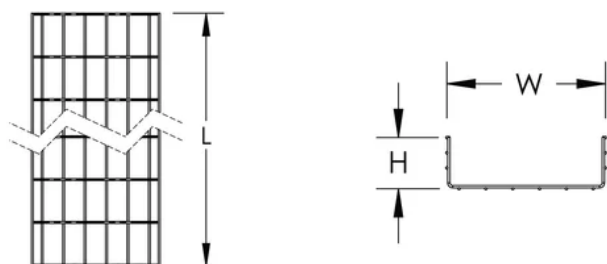

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER