

PESHT HEAVY DUTY PIPE SLIDE, TWO CONNECTORS




FEATURES

For use with two pipe clamps

SPECIFICATIONS

Catalog Number	PESHT
Article Number	580566
Material	Steel
Finish	Electrogalvanized
Rod Size (RS)	12 16
Hole Size (HS)	13 mm
Height (H)	51 mm
Length (L)	275 mm
Δ Length (ΔL)	245 mm
Width (W)	100 mm
A	210 mm
X	13 x 25 mm
Temperature	240 °C Max
Static Load 1 (F1)	9000N
Static Load 2 (F2)	5000N

DIAGRAMS

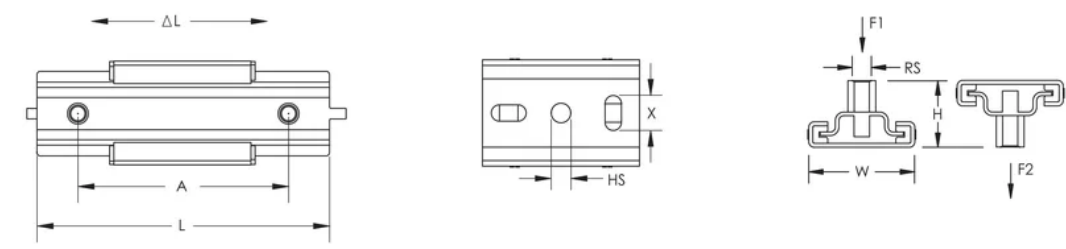

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America
+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe
Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe
Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC
Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER