

PIPE/CABLE CLAMP



FEATURES

Captive threaded stud minimizes the need for additional hardware

With the UNICBAND Sign Support Bracket and Fixoband Strap, attachments to pipe and pole can be made

SPECIFICATIONS

Finish: Hot-Dip Galvanized


Table 1/2

Catalog Number	Article Number	Material	Pipe Size	NB/DN	Outer Diameter (OD)	Width (W)
CR037HD	336300	Steel	3/8"	10	16 - 20 mm	16 mm
CR037S4	336400	Stainless Steel 304 (EN 1.4301)	3/8"	10	16 - 20 mm	16 mm
CR050HD	336310	Steel	1/2"	15	20 - 25 mm	16 mm
CR050S4	336410	Stainless Steel 304 (EN 1.4301)	1/2"	15	20 - 25 mm	16 mm
CR075HD	336320	Steel	3/4"	20	26.9 - 31.8 mm	16 mm
CR075S4	336420	Stainless Steel 304 (EN 1.4301)	3/4"	20	26.9 - 31.8 mm	16 mm
CR087HD	336322	Steel	7/8"		32 - 34 mm	16 mm
CR087S4	336422	Stainless Steel 304 (EN 1.4301)	7/8"		32 - 34 mm	16 mm

Catalog Number	Article Number	Material	Pipe Size	NB/DN	Outer Diameter (OD)	Width (W)
CR100HD	336330	Steel	1"	25	33.7 - 38 mm	20 mm
CR100S4	336430	Stainless Steel 304 (EN 1.4301)	1"	25	33.7 - 38 mm	20 mm
CR125HD	336340	Steel	1 1/4"	32	40.0 - 44.5 mm	20 mm
CR125S4	336440	Stainless Steel 304 (EN 1.4301)	1 1/4"	32	40.0 - 44.5 mm	20 mm
CR150HD	336350	Steel	1 1/2"	40	47 - 51 mm	20 mm
CR150S4	336450	Stainless Steel 304 (EN 1.4301)	1 1/2"	40	47 - 51 mm	20 mm
CR200HD	336360	Steel	2"	50	59.2 - 63.5 mm	20 mm
CR200S4	336460	Stainless Steel 304 (EN 1.4301)	2"	50	59.2 - 63.5 mm	20 mm

Table 2/2			
Catalog Number	Article Number	Static Load 1 (F1)	Static Load 2 (F2)
CR037HD	336300	125N	550N
CR037S4	336400	125N	550N
CR050HD	336310	125N	550N
CR050S4	336410	125N	550N
CR075HD	336320	125N	550N
CR075S4	336420	125N	550N
CR087HD	336322	125N	550N
CR087S4	336422	125N	550N
CR100HD	336330	250N	550N
CR100S4	336430	250N	550N
CR125HD	336340	250N	550N
CR125S4	336440	250N	550N
CR150HD	336350	250N	550N
CR150S4	336450	250N	550N
CR200HD	336360	250N	550N
CR200S4	336460	250N	550N

DIAGRAMS

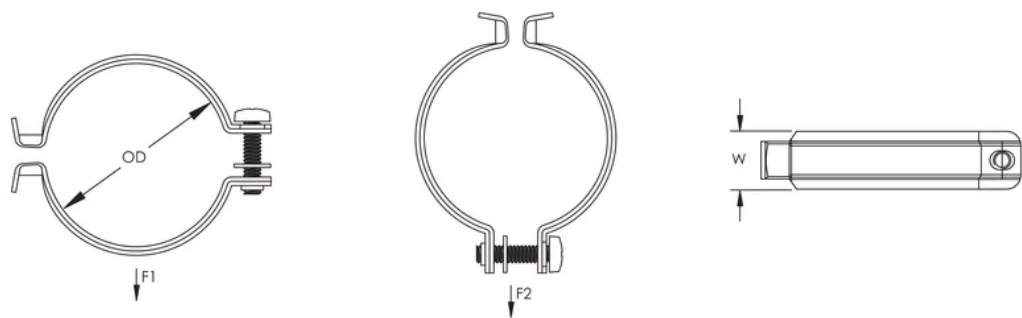

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER