




ROL14 STRUT MOUNTED ROLLER

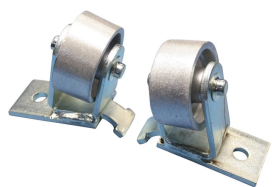

FEATURES


- Designed for strut mounting
- For applications where there is longitudinal pipe movement

SPECIFICATIONS

Table 1/1			
Catalog Number	Material	Finish	Pipe Size
ROL14000EG	Steel	Electrogalvanized	6" - 16"

Pipe Size	Saddle Number	Covering Thickness	Outer Diameter	Radius	A	B
6"	None	0 mm	168.3 mm	84.1 mm	242.9 mm	174.6 mm
	630	25.4 mm	228.6 mm	104.8 mm	258.8 mm	200.0 mm
	631	38.1 mm	254 mm	127 mm	269.9 mm	212.7 mm
	632	50.8 mm	279.4 mm	139.7 mm	279.4 mm	225.4 mm
	633	63.5 mm	304.8 mm	152.4 mm	288.9 mm	238.1 mm
	634	76.2 mm	330.2 mm	165.1 mm	298.4 mm	250.8 mm
	635	104.8 mm	387.3 mm	193.7 mm	317.5 mm	277.8 mm
8"	None	0 mm	219.1 mm	109.5 mm	260.4 mm	198.4 mm
	631	38.1 mm	304.8 mm	152.4 mm	288.9 mm	238.1 mm
	632	50.8 mm	330.2 mm	165.1 mm	298.5 mm	250.8 mm
	633	68.3 mm	365.1 mm	182.6 mm	309.6 mm	265.1 mm
	634	79.4 mm	387.4 mm	193.7 mm	317.5 mm	277.8 mm
	635	104.8 mm	438.1 mm	219.1 mm	336.5 mm	301.6 mm
10"	None	0 mm	273.0 mm	136.5 mm	279.4 mm	223.8 mm
	631	38.1 mm	361.9 mm	181.0 mm	308.0 mm	265.1 mm
	632	52.4 mm	387.3 mm	193.7 mm	317.5 mm	277.8 mm
	633	65.1 mm	412.7 mm	206.4 mm	325.4 mm	288.9 mm
	634	77.8 mm	438.1 mm	219.1 mm	333.4 mm	301.6 mm
	635	103.2 mm	488.9 mm	247.6 mm	352.4 mm	325.4 mm
12"	None	0 mm	323.8 mm	161.9 mm	296.9 mm	247.6 mm
	631	39.7 mm	409.6 mm	204.8 mm	327.0 mm	288.9 mm
	632	52.4 mm	438.1 mm	219.1 mm	336.5 mm	301.6 mm
	633	66.7 mm	463.5 mm	231.8 mm	344.5 mm	312.7 mm
	634	77.8 mm	488.9 mm	244.5 mm	352.4 mm	325.4 mm
	635	104.8 mm	542.9 mm	271.5 mm	371.5 mm	349.2 mm
14"	None	0 mm	355.6 mm	177.8 mm	306.4 mm	261.9 mm
	631	38.1 mm	444.5 mm	222.2 mm	335.0 mm	301.6 mm
	632	50.8 mm	466.7 mm	233.4 mm	344.5 mm	312.7 mm
	633	63.5 mm	492.1 mm	246.1 mm	352.4 mm	325.4 mm
	634	76.2 mm	517.5 mm	258.8 mm	362.0 mm	336.5 mm
	635	101.6 mm	568.3 mm	284.2 mm	378.0 mm	361.9 mm
16"	None	0 mm	406.4 mm	203.2 mm	324.0 mm	287.3 mm
	631	38.1 mm	498.5 mm	249.2 mm	352.4 mm	325.4 mm
	632	50.8 mm	517.5 mm	258.8 mm	376.2 mm	336.5 mm
	633	63.5 mm	549.3 mm	274.6 mm	368.3 mm	349.2 mm
	634	76.2 mm	562.0 mm	281.0 mm	377.8 mm	361.9 mm
	635	101.6 mm	619.1 mm	309.6 mm	393.7 mm	384.2 mm

DIAGRAMS

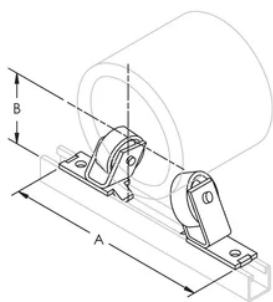

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER